


40 槽宽 8.2 系列铝型材

铝型材

■ 铝型材

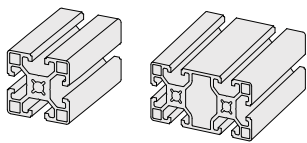

按图定制


自制 库存

材质	表面处理
A6063-T5	喷砂氧化


● 铝型材 40 系列, 适用于中度负载结构: 机器结构框架、物料车、工作台、工厂车间隔断展示架等。

▲ 如需要进行追加工艺, 请参考技术信息。


▲ 长度 $L \leq 6000\text{mm}$, 整根订购可不填。

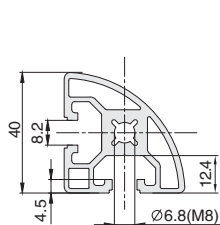


AE40-4040-2-R

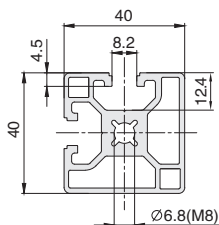


AE40-4040-2-N

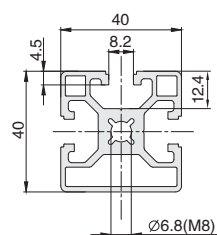


AE40-4040-3

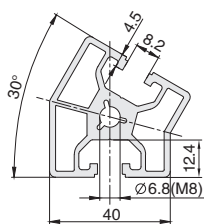


AE40-4430-2

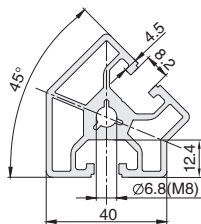


AE40-4445-2

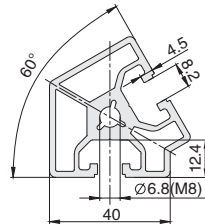


AE40-4460-2

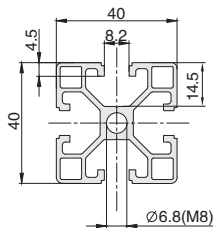


AE40-4040-4-SL

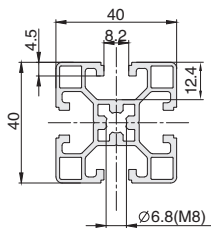

AE40-4040-4-L

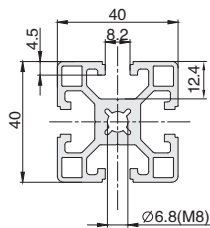


AE40-4040-4

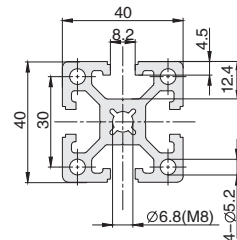


AE40-4040-4-H


05
槽 40
宽 系
8.2 列

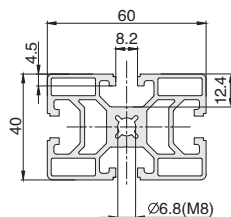


AE40-4060-4

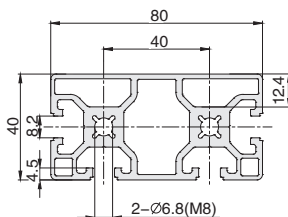

AE40-4080-4

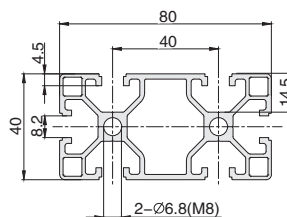


AE40-4080-6-SL

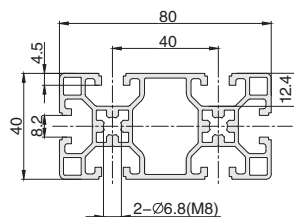


AE40-4080-6-L

40 槽宽 8.2 系列铝型材


铝型材

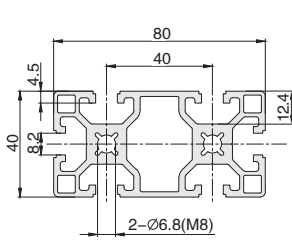


AE40-4080-6

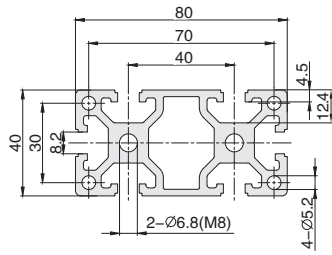


AE40-4080-6-H

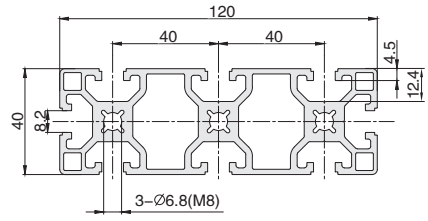


AE40-40120-8

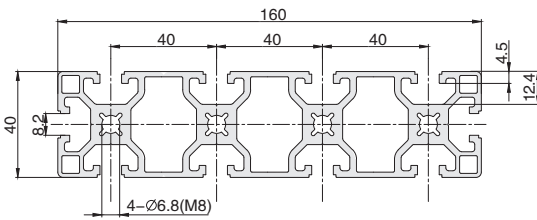


AE40-40160-10

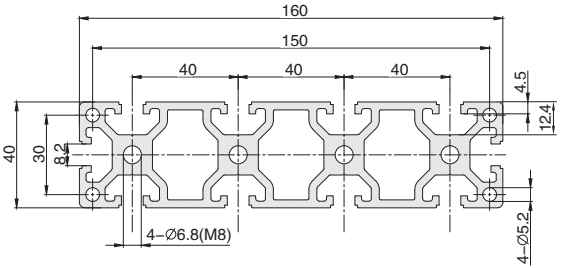


AE40-40160-10-H

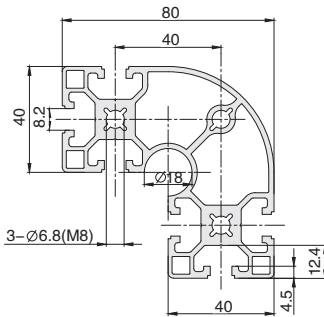


AE40-8840-6-R

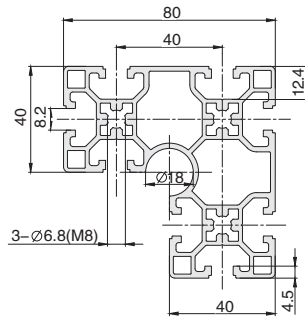


AE40-8840-8

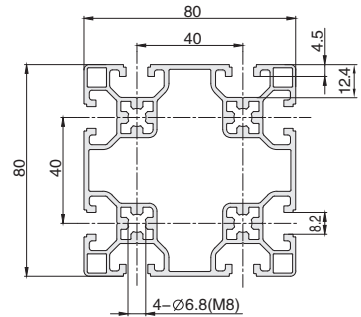


AE40-8080-8-L

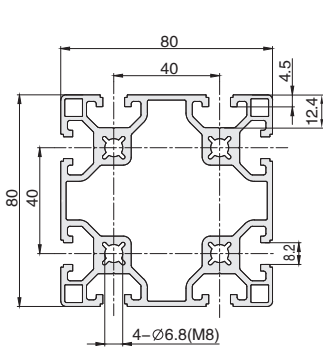

AE40-8080-8

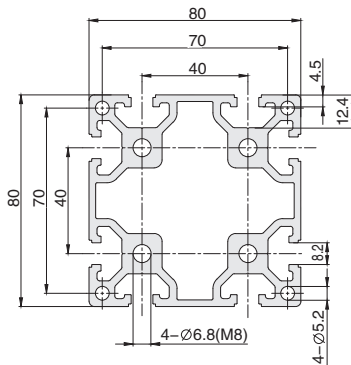


AE40-8080-8-H

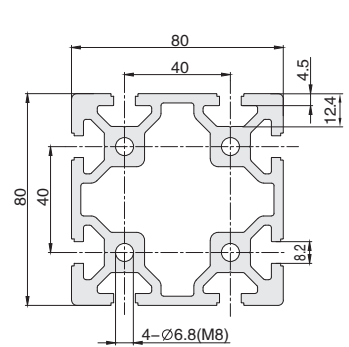


AE40-8080-8-SH

40 槽宽 8.2 系列铝型材

铝型材

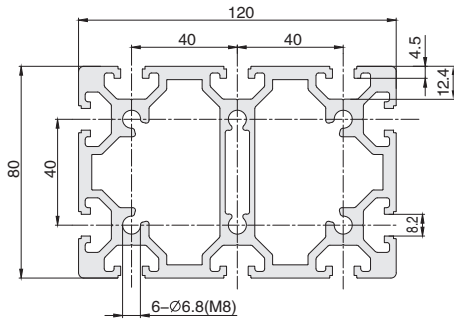

AE40-80120-10

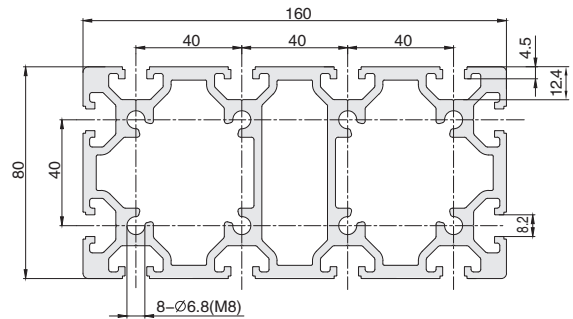

AE40-80160-12

代号	产品描述	截面积 (mm ²)	惯性矩 I _x (cm ⁴)	惯性矩 I _y (cm ⁴)	弯矩 W _x (cm ³)	弯矩 W _y (cm ³)	参考米重 (kg/m)
AE40-4040-2-R	40 系列 40X40 2 槽 R 型	521.71	5.71	8.00	2.86	4.00	1.44
AE40-4040-2-N	40 系列 40X40 2 槽 N 型	559.17	8.18	8.35	4.09	4.18	1.54
AE40-4040-3	40 系列 40X40 3 槽	564.44	8.19	8.26	4.10	4.13	1.55
AE40-4430-2	40 系列 2 槽 30 度	585.71	8.53	8.93	4.27	4.47	1.61
AE40-4445-2	40 系列 2 槽 45 度	584.25	8.54	8.93	4.27	4.46	1.61
AE40-4460-2	40 系列 2 槽 60 度	585.11	8.54	8.97	4.27	4.49	1.61
AE40-4040-4-SL	40 系列 40X40 4 槽 超轻型	450.50	7.23	7.23	3.62	3.62	1.24
AE40-4040-4-L	40 系列 40X40 4 槽 轻型	469.11	7.17	7.17	3.58	3.58	1.29
AE40-4040-4	40 系列 40X40 4 槽	582.32	8.47	8.47	4.23	4.23	1.60
AE40-4040-4-H	40 系列 40X40 4 槽 重型	704.22	11.10	11.10	5.55	5.55	1.94
AE40-4060-4	40 系列 40X60 4 槽	780.54	11.73	24.20	5.87	8.07	2.15
AE40-4080-4	40 系列 40X80 4 槽	1027.01	16.08	62.75	8.04	15.69	2.83
AE40-4080-6-SL	40 系列 40X80 6 槽 超轻型	790.32	13.93	50.51	6.96	12.63	2.18
AE40-4080-6-L	40 系列 40X80 6 槽 轻型	863.84	14.67	56.07	7.33	14.02	2.38
AE40-4080-6	40 系列 40X80 6 槽	1040.45	16.20	63.61	8.10	15.90	2.87
AE40-4080-6-H	40 系列 40X80 6 槽 重型	1237.39	19.91	79.48	9.96	19.87	3.41
AE40-40120-8	40 系列 40X120 8 槽	1500.04	23.94	202.57	11.97	33.76	4.13
AE40-40160-10	40 系列 40X160 10 槽	1957.67	31.67	461.34	15.84	57.67	5.39
AE40-40160-10-H	40 系列 40X160 10 槽 重型	2284.29	37.81	549.83	18.90	68.73	6.29
AE40-8840-6-R	40 系列 80X80 6 槽 R 型	1256.92	33.92	109.00	8.48	27.25	3.46
AE40-8840-8	40 系列 80X80 8 槽 L 型	1302.38	50.65	102.22	12.66	25.56	3.59
AE40-8080-8	40 系列 80X80 8 槽	1571.39	111.84	111.84	55.92	27.96	4.33
AE40-8080-8-L	40 系列 80X80 8 槽 轻型	1316.28	93.43	93.43	23.36	23.36	3.63
AE40-8080-8-H	40 系列 80X80 8 槽 重型	1944.30	137.41	137.41	34.35	34.35	5.35
AE40-8080-8-SH	40 系列 80X80 8 槽 超重型	2257.94	164.31	164.31	41.08	41.08	6.22
AE40-80120-10	40 系列 80X120 10 槽	2700.15	212.73	431.38	106.37	71.90	7.44
AE40-80160-12	40 系列 80X160 12 槽	3457.38	277.84	924.94	138.92	115.62	9.52