






①代号	类型		拔插方向	材质	表面处理
HGCSVC	拔插型	圆孔型	左侧	SUS304	-
HGCSVD			右侧		

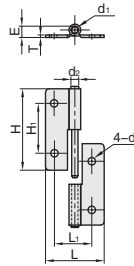


HGCSVC
规格: 52

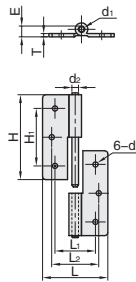


HGCSVC
规格: 65

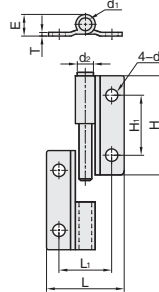

HGCSVD
规格: 52

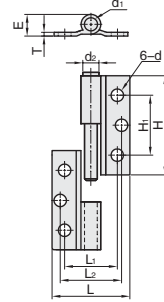

HGCSVD
规格: 65

 

订购编号示例

①代号 - ②规格
HGCSVD - 52

型号		L	H	L ₁	L ₂	H ₁	T	d	d ₁	E	负载 (kg)	参考重量 (kg/pcs)
①代号	②规格											
HGCSVC	52	37.5	52	27	-	30	1.6	6	5	8.5	6	0.04
HGCSVD	65	50	65	31	36	44	2.5	4	5	10.7	7	0.09