

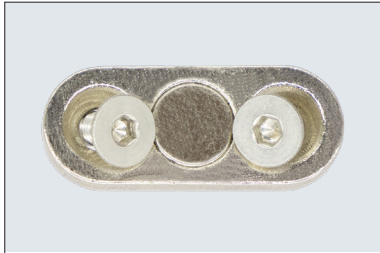


沉孔型

长圆型外壳磁铁

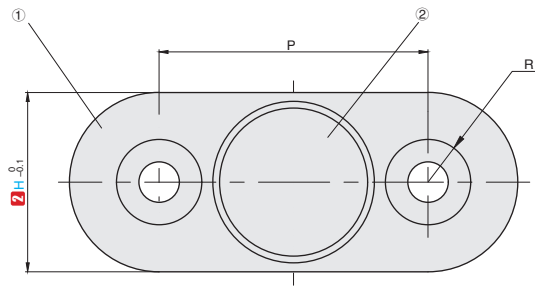

①代号	类型	①		②		③	最高工作温度
		M材质	S表面处理	M材质	S表面处理	M材质	
MTBVXA	沉孔型	45#	无电解镀锌	钕磁铁	镀锌	黄铜	80° C
MTBUXA				钕磁铁			

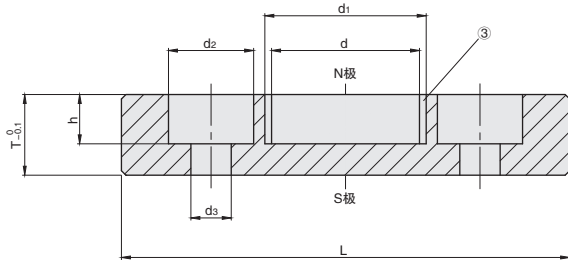

视角标准：第一视角



①代号 - ②H
MTBVXA - H10

①代号	②H	L	P	T	R	h	d	d ₁	d ₂	d ₃	吸附力(kgf)		表面磁通密度高斯(G)	
											MTBVXA	MTBUXA	MTBVXA	MTBVXA
(钕磁铁) MTBVXA (钕磁铁) MTBUXA	10	27	17	7	5	4.5	7	8	8	4.5	0.9	1.4	2500~2900	4100~4600
	13	33	20	7	6.5	4.5	9.5	11	8	4.5	2	3.1	2600~3100	3800~4200
	16	41	25	9	8	5.5	12.5	14	9.5	5.5	3.9	6.5	2700~3300	3800~4200
	20	50	30	10	10	5.5	16.5	18	9.5	5.5	6.2	11.7	2700~3400	3600~3900

▲ 吸附力、表面磁通密度为参考值。

K2
磁铁

