


圆螺母

标准型

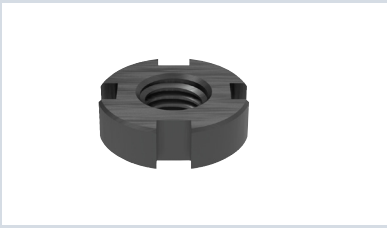


■ 标准型



① 代号	类型	[M] 材质	[S] 表面处理	性能等级
NTCA	圆螺母	45#	发黑	8
NTCB		SUS304	-	-

▲ 适用标准: GB/812

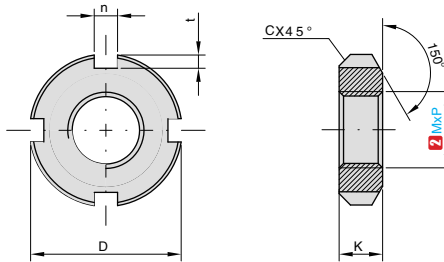

订购编号示例

① 代号	-	② M
NTCA	-	M10

型号		螺距 P	D	K	n (max)	t (max)			
① 代号	② M								
NTCA NTCB	10	1	22	8	4.3	2.6			
	12		25						
	14	1.5	28				10	5.3	3.1
	16		30						
	18		32						
	20		35						
	22		38						
	24		42						
	25								
	27		45						
	30		48						
	33		52						
	35								
	36		55						
	39		58						
	40								
	42	62							
	45	68							
	48								
	50	72	12	8.36	4.25				

F6
垫
螺
片
丝
吊
螺
环
母