
 
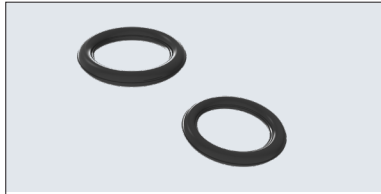


O 型圈

★ 产品特点：性能稳定，耐高温。



①代号	性能	颜色	最高工作温度	④材质
APGTN	耐药品级	黑色	260°C	全氟类氟橡胶 (FFKM)
APGTP	特殊耐热级	黑色	320°C	

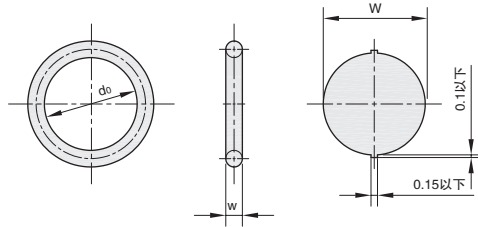

视角标准：第一视角



①代号 - ②标称编号
APGTN - 3

①代号	②标称编号	W	内径		安装尺寸			
			do	APGTN·APGTP	d		D	
			尺寸	公差	尺寸	公差	尺寸	公差
APGTN APGTP	3	1.9±0.08	2.8	±0.16	3	0 -0.05	6	+0.05 0
	4		3.8		4		7	
	5		4.8		5		8	
	6		5.8		6		9	
	7		6.8		7		10	
	8		7.8		8		11	
	9		8.8		9		12	
	10	9.8	±0.20	10	13			
	11	10.8	±0.21	11	15			
	12	11.8	±0.22	12	16			
	14	13.8		14	18			
	15	14.8		15	19			
	16	2.4±0.09	15.8	±0.24	16	0 -0.06	20	+0.06 0
	18	17.8	±0.25	18	22			
	20	19.8	±0.26	20	24			
	21	20.8	±0.27	21	25			
	22	21.8	±0.28	22	26			
	24	23.7		24	30			
	25	24.7		25	31			
	26	3.5±0.1	25.7	±0.31	26	0 -0.08	32	+0.08 0
28	27.7	±0.33	28	34				
29	28.7	±0.34	29	35				
30	29.7		30	36				

▲ 安装尺寸 (d、D) 请参照技术信息。