


①代号	类型	④材质	⑤表面处理	配套轴承④材质	配件
FFSB	法兰型	45#	四氧化三铁保护膜	钢	弹簧挡圈(SS304)
FFSN		45#	无电解镀锌		
FFAY		铝合金	本色阳极氧化		
FCSB	圆弧形	45#	四氧化三铁保护膜		
FCSN		45#	无电解镀锌		
FCAY		铝合金	本色阳极氧化		

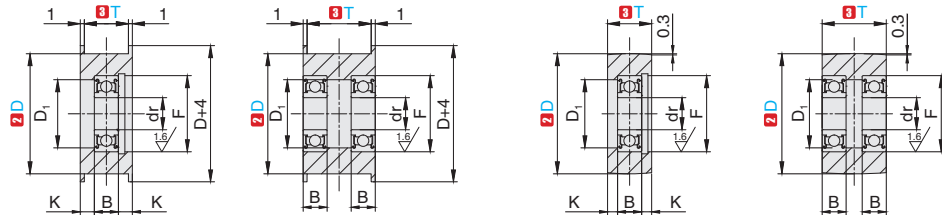

T=6 · 11

法兰型
FFSB
FFSN
FFAY

T=16 · 21 · 27 · 32


T=11

圆弧形
FCSB
FCSN
FCAY

T=16 · 21 · 27 · 32

注：轴承采用压入方式 轴承不可拆卸

 其余 6.3/



视角标准：第一视角



①代号	②D	③T	④追加加工代码
FFSB	D20	T16	
FFSN	D30	T27	FS-31.5
FCSB	D50	T32	FN-52

E1
惰轮
皮带
惰轮

①代号	主要尺寸						配套轴承		
	②D	③T	F	D ₁	K	公称型号			
						dr	B	B	
FFSB FFSN FFAY	15	6	11	9	2	RM69/4-2Z×1	4	4	
	20		16	13	1.5	RM625-2Z×1	5	5	
	20	11	16	13	4	RM625-2Z X1	5	5	
	25		19	16	3.5	RM626-2Z X1	6	6	
	30		19	17	3.5	RM69/8-2ZX1	8	6	
	15		11	9		RM68/5-2Z×2	5	5	
	20	16	16	13		RM625-2Z×2	5	5	
	25		19	16		RM626-2Z×2	6	6	
	30		19	17		RM69/8-2Z×2	8	6	
	35		26	23		R6000-2Z×2	10	8	
	40	26	23		R6000-2Z×2	10	8		
	15	21	11	9		RM68/5-2Z×2	5	5	
	20		16	14		RM68/8-2ZX2	8	5	
	25		19	17		RM69/8-2Z×2	8	6	
	30		19	17		RM69/8-2Z X2	8	6	
	35	26	23		R6000-2Z×2	10	8		
	40	26	23		R6000-2Z×2	10	8		
	50	28	25		-	R6001-2ZX2	12	8	
	15	27	11	9		RM68/5-2Z×2	5	5	
	20		16	14		RM68/8-2Z×2	8	5	
	25		19	17		RM69/8-2Z×2	8	6	
	30		19	17		RM69/8-2ZX2	8	6	
	40	26	23		R6000-2Z×2	10	8		
	50	28	25		R6001-2Z×2	12	8		
	15	32	11	9		RM68/5-2ZX2	5	5	
	20		16	14		RM68/8-2Z×2	8	5	
	25		19	17		RM69/8-2Z×2	8	6	
	30		19	17		RM69/8-2Z ×2	8	6	
	40	26	23		R6000-2Z×2	10	8		
	50	28	25		R6001-2Z ×2	12	8		



① 代号	主要尺寸					配套轴承		
	② D	③ T	F	D ₁	K	公称型号	dr	B
FCSB FCSN FCAY	20	11	16	16	3	RM625-2ZX1	5	5
	25		19	19	2.5	RM626-2ZX1	6	6
	30		19	19	2.5	RM69/8-2ZX1	8	6
	15	16	11	11		RM68/5-2Z X2	5	5
	20		16	16		RM625-2ZX2	5	5
	25		19	19		RM626-2ZX2	6	6
	30		19	19		RM69/8-2ZX2	8	6
	35		22	17		R6900-2Z×2	10	6
	40		22	17		R6900-2Z×2	10	6
	15	21	11	9		RM68/5-2ZX2	5	5
	20		16	14		RM68/8-2Z×2	8	5
	25		19	17		RM69/8-2Z×2	8	6
	30		19	17		RM69/8-2ZX2	8	6
	35		26	23		R6000-2Z ×2	10	8
	40		26	23		R6000-2Z×2	10	8
	50		28	25		R6001-2Z ×2	12	8
	15	27	11	9	-	RM68/5-2Z×2	5	5
	20		16	14		RM68/8-2Z×2	8	5
	25		19	17		RM69/8-2Z ×2	8	6
	30		19	17		RM69/8-2Z×2	8	6
	40		26	23		R6000-2Z×2	10	8
	50		28	25		R6001-2Z ×2	12	8
	15	32	11	9		RM68/5-2Z ×2	5	5
	20		16	14		RM68/8-2Z×2	8	5
	25		19	17		RM69/8-2Z×2	8	6
30		19	17		RM69/8-2Z ×2	8	6	
40		26	23		R6000-2Z×2	10	8	
50		28	25		R6001-2Z×2	12	8	



④ 追加工类型	法兰缩短	单边法兰缩短	单侧去除法兰	法兰厚度减小
代号	FS	FST	FSG	FN
示例图				
详细信息	以0.5mm为单位切割缩短法兰高度 D≤FS<D+4 圆弧型不适用	切割单侧法兰缩短高度 圆弧型不适用 不可与FSG并用	去除如图右侧法兰 圆弧型不适用 同时指定法兰缩短与单侧去除法兰时, 请同时使用FS和FSG	将法兰厚度变更为0.5mm, 整体尺寸缩减1mm 圆弧型不适用
指定方法	FS-18.5	FST	FSG	FN

E1
惰皮带
惰轮

