 



■ T型锁紧销



①代号	M材质					
	销	弹簧	把手	钢珠	按钮	环
LPVS	不锈钢	不锈钢	铝合金	不锈钢	铝合金	不锈钢

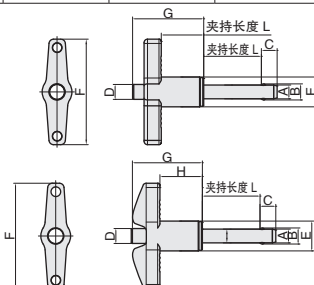

视角标准：第一视角




①代号 - ②A - ③L
LPVS - A5 - L20



①代号	②A -0.04 -0.08	夹持长度(选择) ③L +0.5 0	B	C	D	E	F	G	H
LPVS	5		5.5	7	6.5	13.1	46.1	31.3	18.5
	6		7	7	6.5	13.1	46.1	31.3	18.5
	8		9.5	8	6.5	13.1	46.1	31.3	18.5
	10	10 15 20 25 30	12	9	7.7	15	51.1	36.1	22.5
	12	35 40 45 50 55	14.5	10	7.7	15	51.1	36.1	22.5
	14	60 65 70 75 80	16.5	11	14	23.9	78.7	49.8	33.6
	16	85 90 95 100	19	14	14	23.9	78.7	49.8	33.6
	20		24.08	19	14	23.9	78.7	49.8	33.6
	25		32	22	17.5	30	88.9	55.9	33.9

▲A参数为5/6/8/10/12, 产品为A型
▲A参数为14/16/20/25, 产品为B型

■ L型锁紧销

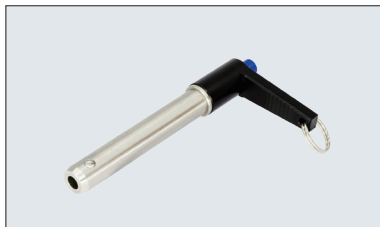

①代号	M材质					
	销	弹簧	把手	钢珠	按钮	环
LPVT	不锈钢	不锈钢	铝合金	不锈钢	铝合金	不锈钢

 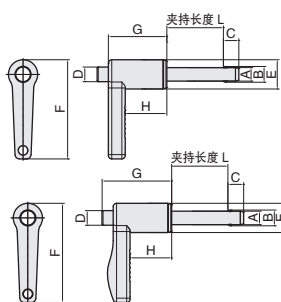

视角标准：第一视角



①代号 - ②A - ③L
LPVT - A5 - L20

①代号	②A -0.04 -0.08	夹持长度(选择) ③L +0.5 0	B	C	D	E	F	G	H
LPVT	5		5.5	7	6.5	13.1	46.1	31.3	18.5
	6		7	7	6.5	13.1	46.1	31.3	18.5
	8		9.5	8	6.5	13.1	46.1	31.3	18.5
	10	10 15 20 25 30	12	9	7.7	15	51.1	36.1	22.5
	12	35 40 45 50 55	14.5	10	7.7	15	51.1	36.1	22.5
	14	60 65 70 75 80	16.5	11	14	23.9	78.7	49.8	33.6
	16	85 90 95 100	19	14	14	23.9	78.7	49.8	33.6
	20		24.08	19	14	23.9	78.7	49.8	33.6
	25		32	22	17.5	30	88.9	55.9	33.9

▲A参数为5/6/8/10/12, 产品为A型
▲A参数为14/16/20/25, 产品为B型