


高精度型/内螺纹型

直杆球锥角型圆柱销

★ 产品特点：方便定位，多种长度可选。

■ 高精度型

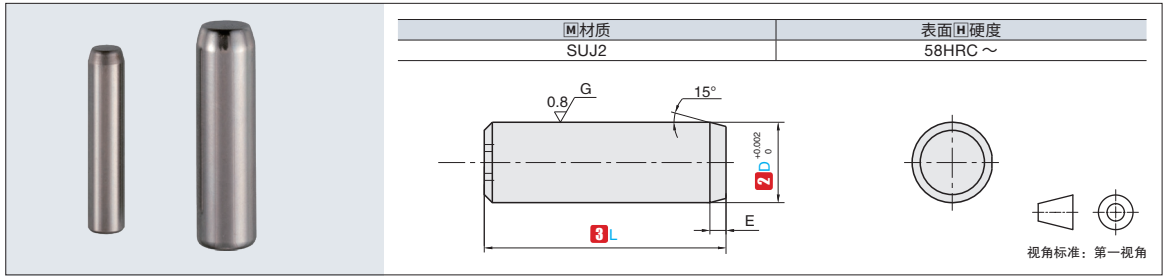


①代号 - ②D - ③L
CPLH - D8 - L20

①代号	②D	③L						E		
CPLH	2	6	8	10				1		
	3		8	10	15	20	25	30	1	
	4			10	15	20	25	30	1.5	
	5			10	15	20	25	30	1.5	
	6			10	15	20	25	30	2	
	8					20	30	40	50	2.5
	10						30	40	50	60

★ 产品特点：杆部有斜度，方便插拔。

■ 内螺纹型

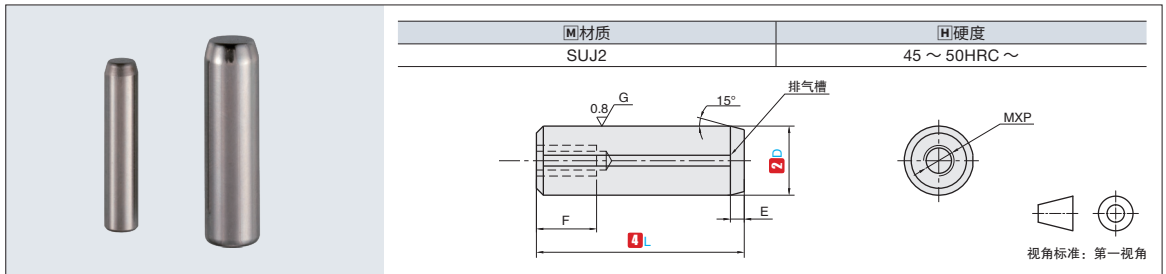

①代号 - ②D - ③公差 - ④L
CPEG - D8 - p6 - L20

①代号	②D	③公差	④L									E	F	MxP				
CPEG	5		10	15	20	25	30						1.5	6	3×0.5			
	6		10	15	20	25	30	35	40	50			2	8	4×0.7			
	8	m6	15	20	25	30	35	40	45	50	60	70	80	2	8	5×0.8		
	10	p6	15	20	25	30	35	40	45	50	60	70	80	(100)	(120)	2.5	10	6×1.0
	12	h7	20	30	40	50	60	70	80	(100)	(120)			2.5	10	6×1.0		
	13	t				40	50	60	70	80	(100)	(120)		2.5	15	8×1.25		
	16					40	50	60	70	80	(100)	(120)	(150)	3	15	8×1.25		
20	m6								50	60	70	80		3	18	10×1.5		
		p6																

▲ 当D=5或6, L=10时底孔可能贯通。

▲ 当D=5 L=10时 F=6。

▲ () 内的L尺寸只有公差h7可以选择。

▲ p6公差带尾部识别槽。

D	③D公差			
	m6	p6	h7	t
5~6	+0.012 +0.004	+0.020 +0.012	0 -0.012	+0.010 +0.005
8~10	+0.015 +0.006	+0.024 +0.015	0 -0.015	
12~16	+0.018 +0.007	+0.029 +0.018	0 -0.018	
20	+0.021 +0.008	+0.035 +0.022	0 -0.021	

K1
平键挡圈开口销
圆柱销油嘴

分类
目录



返回
主目录

