



## Raccord mâle droit NPT en acier inoxydable AISI-316

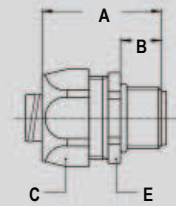

| Filetage | Sealtite<br>(Pouce) | Diam. intérieur<br>Min. (mm) | Dimensions en mm |    |    |   |    | Condition.<br>Standard | Référence<br>Article | Poids<br>(Kg/100) |
|----------|---------------------|------------------------------|------------------|----|----|---|----|------------------------|----------------------|-------------------|
|          |                     |                              | A                | B  | C  | D | E  |                        |                      |                   |
| 1/2" NPT | 3/8"                | 10,2                         | 35               | 12 | 26 | - | 24 | 10                     | 814.112.9            | 6,0               |
| 1/2" NPT | 1/2"                | 13,9                         | 37               | 13 | 29 | - | 27 | 10                     | 814.116.9            | 6,7               |
| 3/4" NPT | 3/4"                | 18,5                         | 40               | 15 | 35 | - | 33 | 5                      | 814.120.9            | 9,6               |
| 1" NPT   | 1"                  | 23,8                         | 46               | 15 | 45 | - | 43 | 5                      | 814.126.9            | 27,0              |

## Raccord 90 °mâle NPT en acier inoxydable AISI-316

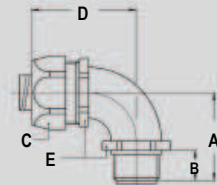

| Filetage | Sealtite<br>(Pouce) | Diam. intérieur<br>Min. (mm) | Dimensions en mm |    |    |    |    | Condition.<br>Standard | Référence<br>Article | Poids<br>(Kg/100) |
|----------|---------------------|------------------------------|------------------|----|----|----|----|------------------------|----------------------|-------------------|
|          |                     |                              | A                | B  | C  | D  | E  |                        |                      |                   |
| 1/2" NPT | 3/8"                | 10,2                         | 36               | 13 | 27 | 43 | 22 | 10                     | 814.512.9            | 14,4              |
| 1/2" NPT | 1/2"                | 13,9                         | 36               | 13 | 30 | 43 | 27 | 10                     | 814.516.9            | 15,8              |
| 3/4" NPT | 3/4"                | 18,5                         | 43               | 15 | 36 | 48 | 33 | 5                      | 814.520.9            | 23,8              |

## Ecrou ISO en acier inoxydable AISI-316



| Filetage  | Sealtite<br>(Pouce) | Diam. intérieur<br>Min. (mm) | Dimensions en mm |   |    |   |   | Condition.<br>Standard | Référence<br>Article | Poids<br>(Kg/100) |
|-----------|---------------------|------------------------------|------------------|---|----|---|---|------------------------|----------------------|-------------------|
|           |                     |                              | A                | B | C  | D | E |                        |                      |                   |
| M16 x 1,5 | -                   | -                            | 2,8              | - | 19 | - | - | 50                     | 880.116.8            | 0,5               |
| M20 x 1,5 | -                   | -                            | 3,5              | - | 24 | - | - | 50                     | 880.120.8            | 0,7               |
| M25 x 1,5 | -                   | -                            | 3,5              | - | 30 | - | - | 25                     | 880.125.8            | 1,1               |
| M32 x 1,5 | -                   | -                            | 4,5              | - | 35 | - | - | 20                     | 880.132.8            | 2,4               |

## Ecrou NPT en acier inoxydable AISI-316



| Filetage | Sealtite<br>(Pouce) | Diam. intérieur<br>Min. (mm) | Dimensions en mm |   |    |   |   | Condition.<br>Standard | Référence<br>Article | Poids<br>(Kg/100) |
|----------|---------------------|------------------------------|------------------|---|----|---|---|------------------------|----------------------|-------------------|
|          |                     |                              | A                | B | C  | D | E |                        |                      |                   |
| NPT 1/2" | -                   | -                            | 5,0              | - | 24 | - | - | 50                     | 880.216.8            | 1,1               |
| NPT 3/4" | -                   | -                            | 7,0              | - | 30 | - | - | 50                     | 880.220.8            | 2,2               |
| NPT 1"   | -                   | -                            | 7,0              | - | 36 | - | - | 25                     | 880.226.8            | 2,7               |

## Virole de continuité en acier inoxydable AISI-316



| Filetage | Sealtite<br>(Pouce) | Diam. intérieur<br>Min. (mm) | Dimensions en mm |   |   |   |   | Condition.<br>Standard | Référence<br>Article | Poids<br>(Kg/100) |
|----------|---------------------|------------------------------|------------------|---|---|---|---|------------------------|----------------------|-------------------|
|          |                     |                              | A                | B | C | D | E |                        |                      |                   |
| -        | 3/8"                | 10,2                         | -                | - | - | - | - | 10                     | 815.011.9            | 0,7               |
| -        | 1/2"                | 13,9                         | -                | - | - | - | - | 10                     | 815.016.9            | 1,0               |
| -        | 3/4"                | 18,5                         | -                | - | - | - | - | 5                      | 815.021.9            | 1,7               |