



**Pg gerade Verschraubung, Aussengewinde, Messing-vernickelt (einschl. Einschraubset).**

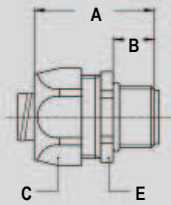


Gewinde	SL / SLI NW (Zoll)	Min. Innen Durchm. (mm)	Abmessungen in mm					Standard Verpackung	Artikel Nummer	Gewicht (Kg/100)
			A	B	C	D	E			
Pg 9	5/16"	8,3	35	12	26	-	24	10	810.009.6	4,8
Pg 11	5/16"	8,3	35	12	26	-	24	10	810.012.6	5,6
Pg 9	3/8"	10,2	35	12	26	-	24	10	810.010.6	6,6
Pg 11	3/8"	10,2	35	12	26	-	24	10	810.011.6	7,4
Pg 13,5	3/8"	10,2	35	12	26	-	24	10	810.013.6	7,4
Pg 16	1/2"	13,6	37	13	29	-	27	10	810.016.6	8,1
Pg 21	3/4"	18,5	40	15	35	-	33	5	810.021.6	11,4
Pg 29	1"	23,8	46	15	45	-	43	5	810.029.6	28,0
Pg 36	1.1/4"	31,8	52	16	54	-	52	2	810.036.6	37,4

**Pg gerade Verschraubung, Innengewinde, Messing-vernickelt (einschl. Einschraubset).**

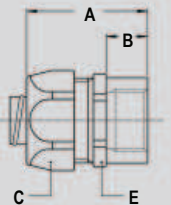


Gewinde	SL / SLI NW (Zoll)	Min. Innen Durchm. (mm)	Abmessungen in mm					Standard Verpackung	Artikel Nummer	Gewicht (Kg/100)
			A	B	C	D	E			
Pg 11	5/16"	8,3	35	12	26	-	24	10	810.312.6	5,3
Pg 13,5	5/16"	8,3	35	12	26	-	24	10	810.314.6	5,6
Pg 11	3/8"	10,2	35	12	26	-	24	10	810.311.6	7,1
Pg 13,5	3/8"	10,2	35	12	26	-	24	10	810.313.6	7,4
Pg 16	1/2"	13,6	37	13	29	-	27	10	810.316.6	8,1
Pg 21	3/4"	18,5	40	15	35	-	33	5	810.321.6	12,3
Pg 29	1"	23,8	46	15	45	-	43	5	810.329.6	23,7
Pg 36	1.1/4"	31,8	52	16	54	-	52	2	810.336.6	32,1

**Pg 90° Winkel Verschraubung, Aussengewinde, Messing-vernickelt (einschl. Einschraubset).**

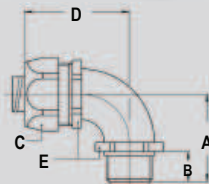

Gewinde	SL / SLI NW (Zoll)	Min. Innen Durchm. (mm)	Abmessungen in mm					Standard Verpackung	Artikel Nummer	Gewicht (Kg/100)
			A	B	C	D	E			
Pg 11	5/16"	8,3	32	12	26	42	22	10	810.912.6	8,9
Pg 13,5	5/16"	8,3	32	12	26	42	22	10	810.914.6	8,9
Pg 11	3/8"	10,2	32	12	26	42	22	10	810.911.6	10,7
Pg 13,5	3/8"	10,2	32	12	26	42	22	10	810.913.6	10,7
Pg 16	1/2"	13,6	36	13	29	43	27	10	810.916.6	17,1
Pg 21	3/4"	18,5	43	15	35	48	33	5	810.921.6	24,6
Pg 29	1"	23,8	48	15	45	59	42	5	810.929.6	38,3
Pg 36	1.1/4"	31,8	57	16	54	68	51	2	810.936.6	65,3

**Pg gerade Kabel-Schlauch-Verschraubung, Aussengewinde, Messing-vernickelt (einschl. Einschraubset).**

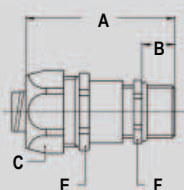

Gewinde	SL / SLI NW (Zoll)	Klemm- bereich (mm)	Abmessungen in mm					Standard Verpackung	Artikel Nummer	Gewicht (Kg/100)
			A	B	C	E	F			
Pg 9	5/16"	5 - 8	55	10	26	24	17	10	810.709.6	7,8
Pg 11	5/16"	5 - 8	55	10	26	24	20	10	810.714.6	9,5
Pg 9	3/8"	5 - 8	55	10	26	24	20	10	810.712.6	9,6
Pg 11	3/8"	5 - 9,8	55	10	26	24	20	10	810.711.6	11,3
Pg 13,5	1/2"	6 - 12	57	10	29	27	22	10	810.715.6	11,5
Pg 16	1/2"	10 - 13,9	60	10	29	27	24	10	810.716.6	13,5
Pg 21	3/4"	13 - 18	67	12	35	33	30	5	810.721.6	22,6
Pg 29	1"	18 - 22,8	80	12	45	43	40	5	810.729.6	38,4

ANACONDA  
MULTIFLEX

VERSCHRAU-  
BUNGEN FÜR  
TYP SL / SLI  
IP 40