



5 TEILIGE VERSCHRAUBUNG FCE-LFHB, IP 65, MESSING-VERNICKELT



ISO 45° Compact Verschraubung, Aussengewinde, Messing-vernickelt (einschl. Einschraubset).

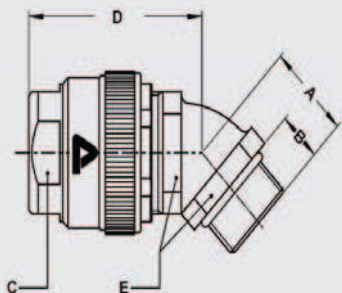


Gewinde	FCE-LFHB	Min. Innen Durchm. mm	Abmessungen in mm					Standard Verpack.	Artikel Nummer	Gewicht (Kg/100)
			A	B	C	D	E			
M16 x 1,5	16	11,2	19	10	24	44	22	10	732.416.4	12,5
M20 x 1,5	16	11,2	20	10	24	45	24	10	732.417.4	13,5
M20 x 1,5	20	15,2	21	10	28	50	27	10	732.420.4	15,8
M25 x 1,5	25	19,2	23	10	34	53	33	5	732.425.4	23,5
M32 x 1,5	32	25,9	28	12	41	61	42	5	732.432.4	38,5

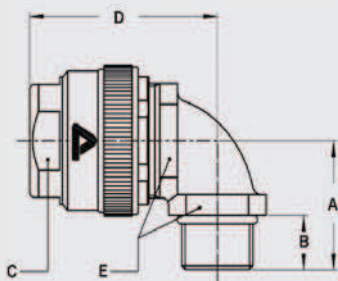

ISO 90° Compact Verschraubung, Aussengewinde, Messing-vernickelt (einschl. Einschraubset).



Gewinde	FCE-LFHB	Min. Innen Durchm. mm	Abmessungen in mm					Standard Verpack.	Artikel Nummer	Gewicht (Kg/100)
			A	B	C	D	E			
M16 x 1,5	16	11,2	26	10	24	48	22	10	732.916.4	13,0
M20 x 1,5	16	11,2	26	10	24	49	24	10	732.917.4	14,0
M20 x 1,5	20	15,2	28	10	28	54	27	10	732.920.4	16,5
M25 x 1,5	25	19,2	32	10	34	61	33	5	732.925.4	24,0
M32 x 1,5	32	25,9	40	12	41	69	42	5	732.932.4	39,0

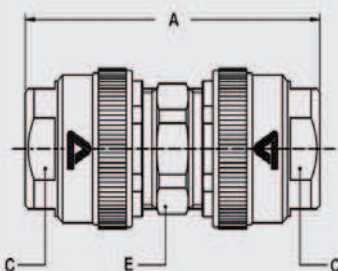

Schlauchverbinder, Messing-vernickelt (einschl. Einschraubset).



Gewinde	FCE-LFHB	Min. Innen Durchm. mm	Abmessungen in mm					Standard Verpack.	Artikel Nummer	Gewicht (Kg/100)
			A	B	C	D	E			
-	16	11,2	75	-	24	-	24	10	785.012.4	18,5
-	20	15,2	84	-	28	-	27	10	785.016.4	21,5
-	25	19,2	88	-	34	-	33	5	785.020.4	29,5
-	32	25,9	96	-	41	-	44	5	785.026.4	48,0