



# ART 500


Special Applications

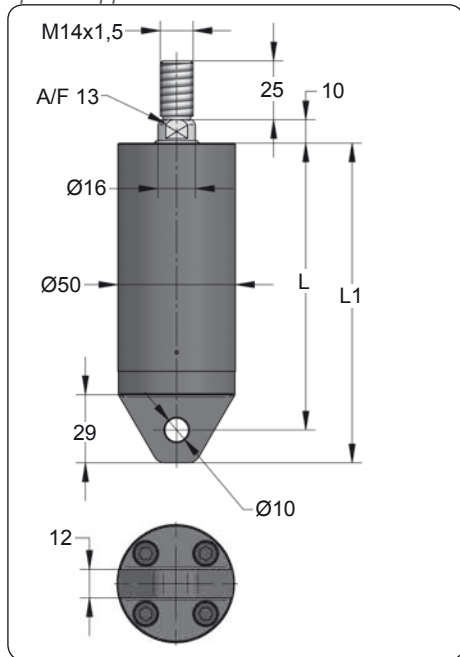

ORDER	S (mm)	L1 ±0,25 (mm)	L (mm)	Kg.
ART 500 015	15	136	122	1.50
ART 500 025	25	156	142	1.64
ART 500 038	38	182	168	1.82
ART 500 050	50	206	192	1.99
ART 500 080	80	266	252	2.41
ART 500 100	100	306	292	2.69
ART 500 125	125	356	342	3.05
ART 500 160	160	426	412	3.54

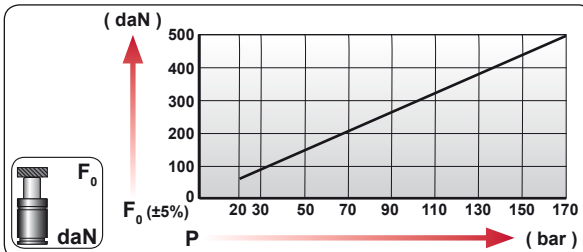

CODE					
		bar	psi		
ART 500 050		170	2465	500	670
-----		---	---	---	---

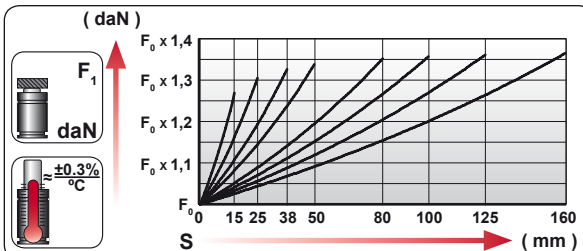

	ENG ORDER		
	DEU BESTELLUNG	daN	mm
	FRA COMMANDE		
	ITA ORDINE		
	ESP PEDIDO		
POR PEDIDO			

ART 500 50

ART 500 050

	SEAL KIT S-XXXXXXX		CARTRIDGE KIT C-XXXXXXX	
	<b>KIT S-XXXXXXX</b>		<b>KIT C-XXXXXXX</b>	
ENG DEU	REPAIR KIT ERSATZ	CHARGING ADAPTER LADEADAPTER		
FRA	KIT DE RÉPARATION	RACCORD DE CHARGE		
ITA	KIT DI MANUTENZIONE	ADATTATORE DI CARICO		
ESP	KIT DE REPARACION	ADAPTADOR DE CARGA		
POR	KIT DE MANUTENÇÃO	ADAPTADOR DE CARGA		

N <sub>2</sub>	Smax < 90%	Vmax 0,5 m/s	bar psi 20 290	bar psi 170 2465	°C °F 0 32	°C °F 80 176	