
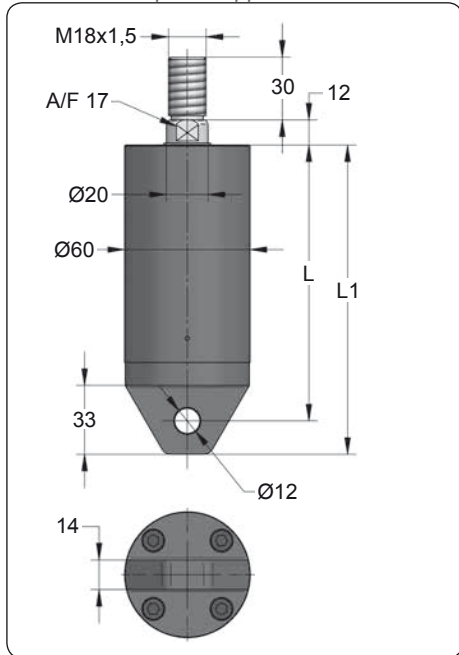


# AZOL GAS ART 750


Special Applications

ORDER	S (mm)	L1 ±0,25 (mm)	L (mm)	Kg.
ART 750 015	15	148	132	2.32
ART 750 025	25	168	152	2.52
ART 750 038	38	194	178	2.77
ART 750 050	50	218	202	3.00
ART 750 080	80	278	262	3.59
ART 750 100	100	318	302	3.98
ART 750 125	125	368	352	4.47
ART 750 160	160	438	422	5.16

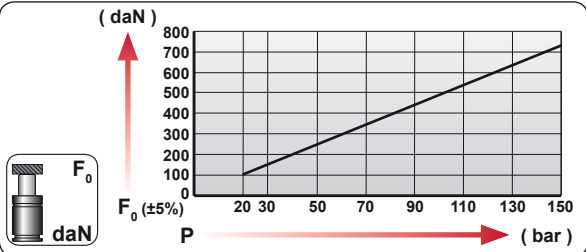

CODE				
	bar	psi	daN	daN
ART 750 050	150	2175	735	1010
-----	---	---	---	---

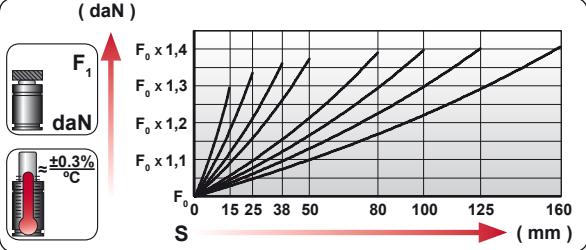

	ENG ORDER		
	DEU BESTELLUNG	daN	mm
	FRA COMMANDE		
	ITA ORDINE		
	ESP PEDIDO		
POR PEDIDO			

**ART 750 50**

**ART 750 050**

SEAL KIT S-XXXXXXX	CARTRIDGE KIT C-XXXXXXX	
<b>KIT S-XXXXXXX</b>		<b>18 CG 1-Q</b>
<b>KIT C-XXXXXXX</b>		
ENG REPAIR KIT	CHARGING ADAPTER	
DEU ERSATZ	LADEADAPTER	
FRA KIT DE RÉPARATION	RACCORD DE CHARGE	
ITA KIT DI MANUTENZIONE	ADATTATORE DI CARICO	
ESP KIT DE REPARACION	ADAPTADOR DE CARGA	
POR KIT DE MANUTENÇÃO	ADAPTADOR DE CARGA	

N <sub>2</sub>	S <sub>max</sub> < 90%	V <sub>max</sub> 0,5 m/s	P <sub>min</sub> (20°C)	P <sub>max</sub> (20°C)	T <sub>min</sub>	T <sub>max</sub>	

bar	psi	bar	psi	°C	°F	°C	°F	<b>X</b>
20	290	150	2175	0	32	80	176	