



# EFGC 16

Gas Strippers


		RENAULT EM24.54.300

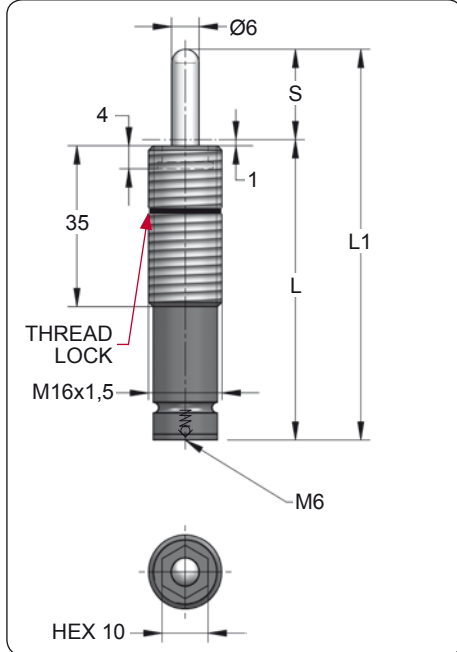

CODE	S (mm)	L1 ±0,25 (mm)	L (mm)	Kg.
EFGC 16 ... 010	10	65	55	0.06
EFGC 16 ... 020	20	85	65	0.07
EFGC 16 ... 030	30	105	75	0.07
EFGC 16 ... 040	40	125	85	0.08
EFGC 16 ... 050	50	145	95	0.09
EFGC 16 ... 060	60	165	105	0.09
EFGC 16 ... 070	70	185	115	0.10
EFGC 16 ... 080	80	205	125	0.10
EFGC 16 ... 100	100	245	145	0.12
EFGC 16 ... 125	125	295	170	0.13

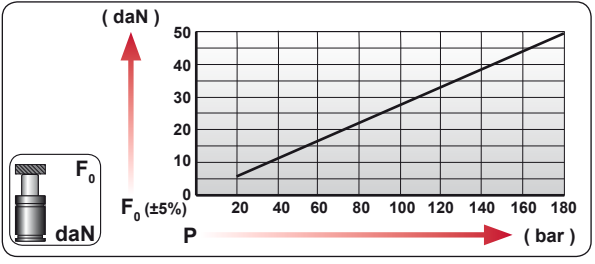


CODE	COLOR	Pressure		Force	
		bar	psi	daN	daN
EFGC 16 6 050	Green	20	290	6	8
EFGC 16 11 050	Blue	40	580	11	15
EFGC 16 21 050	Red	75	1090	21	30
EFGC 16 42 050	Yellow	150	2175	42	55
EFGC 16 XX 050	Black	20-180	290-2610	6 - 50	8 - 70

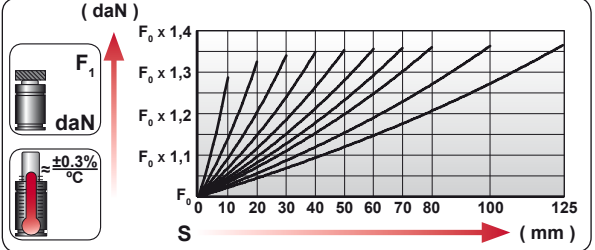

	ENG ORDER		
	DEU BESTELLUNG		
	FRA COMMANDE		
	ITA ORDINE		
	ESP PEDIDO		
POR PEDIDO			

**EFGC 16 50 50**


**EFGC 16 50 050**

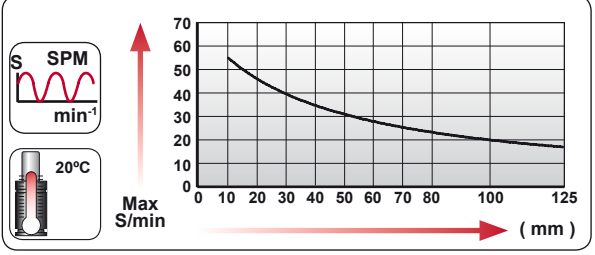







--	--	--	--	--	--	--	--

N <sub>2</sub>	S <sub>max</sub> < 90%	V <sub>max</sub> 1,6 m/s	bar psi	bar psi	°C °F	°C °F	°C °F	
			20 290	180 2610	0 32	80 176		

**LPT 10**

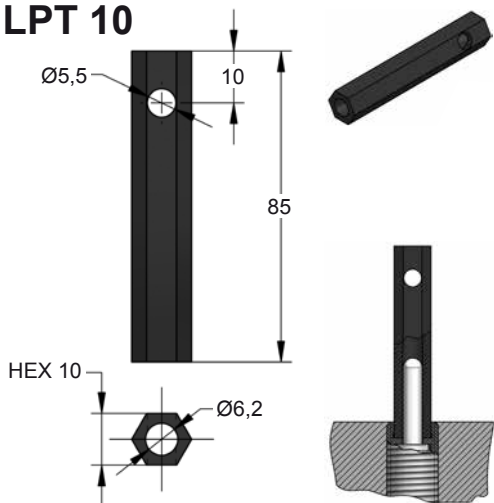

**E23-016**

  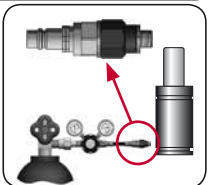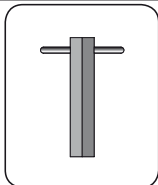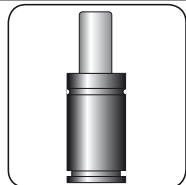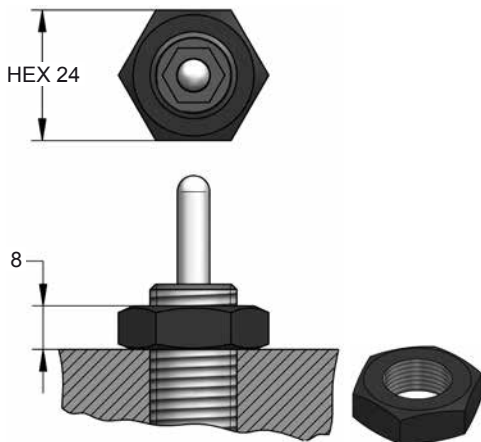

CODE	EFGC 16 50 050	<b>X</b>	LPT 10	06 CG 2-Q
ENG ORDER	GAS SPRING	REPAIR KIT	KEY	CHARGING ADAPTER
DEU BESTELLUNG	GASDRUCKFEDER	ERSATZTEILSATZ	MONTAGESCHLÜSSEL	LADEADAPTER
FRA COMMANDE	RESSORT À GAZ	KIT DE RÉPARATION	CLE	RACCORD DE CHARGE
ITA ORDINE	CILINDRO AD AZOTO	KIT DI MANUTENZIONE	CHIAVE	ADATTATORE DI CARICO
ESP PEDIDO	RESORTE DE GAS	KIT DE REPARACION	LLAVE	ADAPTADOR DE CARGA
POR PEDIDO	CILINDRO DE GÁS	KIT DE MANUTENÇÃO	CHAVE	ADAPTADOR DE CARGA