



EFGQ 16

Gas Strippers


FORD W-DX35-8031

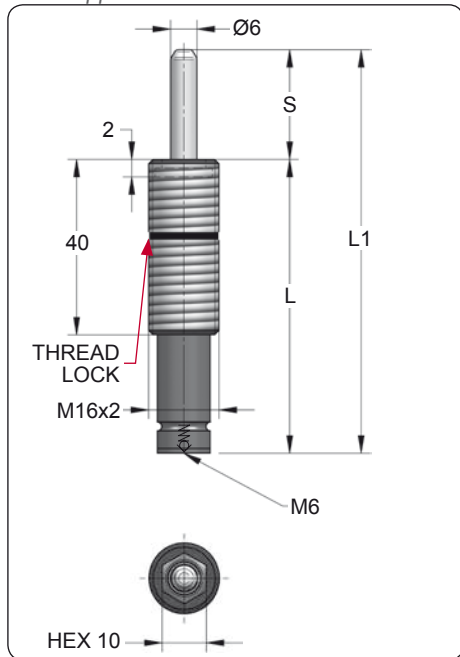

CODE	S (mm)	L1 ±0,25 (mm)	L (mm)	Kg.
EFGQ 16 ... 007	7	56	49	0.06
EFGQ 16 ... 010	10	62	52	0.06
EFGQ 16 ... 012	12.7	67.4	54.7	0.06
EFGQ 16 ... 015	15	72	57	0.07
EFGQ 16 ... 025	25	92	67	0.07
EFGQ 16 ... 038	38	118	80	0.08
EFGQ 16 ... 050	50	142	92	0.09
EFGQ 16 ... 063	63.5	172	108.5	0.09
EFGQ 16 ... 080	80	205	125	0.10

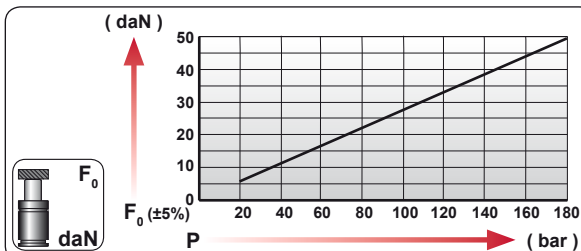


CODE	COLOR	Pressure		Force	
		bar	psi	daN	daN
EFGQ 16 13 050	Green	45	650	13	20
EFGQ 16 25 050	Blue	90	1305	25	40
EFGQ 16 38 050	Red	135	1960	38	60
EFGQ 16 50 050	Yellow	180	2610	50	80
EFGQ 16 XX 050	Black	20-180	290-2610	6 - 50	8 - 80

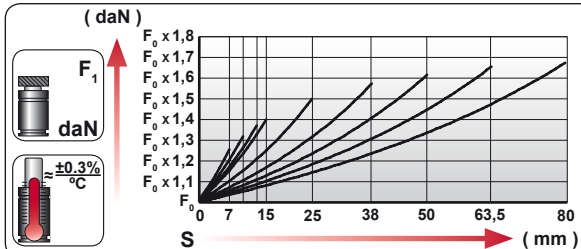

	ENG ORDER		
	DEU BESTELLUNG		
	FRA COMMANDE		
	ITA ORDINE		
	ESP PEDIDO		
POR PEDIDO			

EFGQ 16 50 50


EFGQ 16 50 050

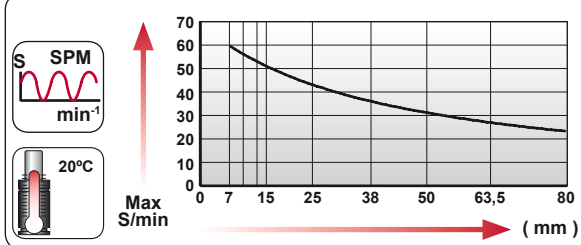







N ₂	S _{max} < 90%	V _{max} 1,6 m/s	P _{min} (20°C)	P _{max} (20°C)	T _{min}	T _{max}	

bar	psi	bar	psi	°C	°F	°C	°F	X
20	290	180	2610	0	32	80	176	

LPT 10

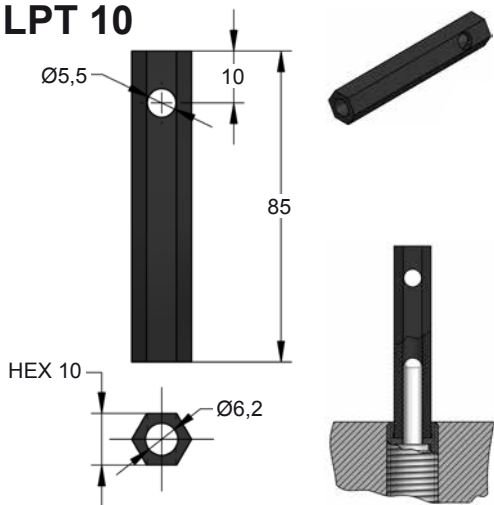

E63-016

  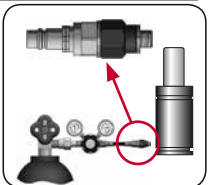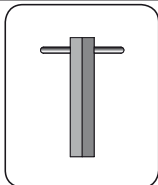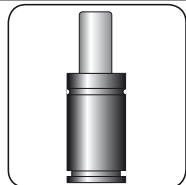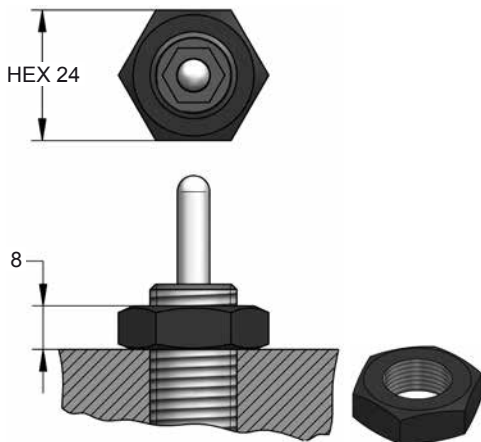

CODE	EFGQ 16 50 050	X	LPT 10	06 CG 2-Q
ENG ORDER	GAS SPRING	REPAIR KIT	KEY	CHARGING ADAPTER
DEU BESTELLUNG	GASDRUCKFEDER	ERSATZTEILSATZ	MONTAGESCHLÜSSEL	LADEADAPTER
FRA COMMANDE	RESSORT À GAZ	KIT DE RÉPARATION	CLE	RACCORD DE CHARGE
ITA ORDINE	CILINDRO AD AZOTO	KIT DI MANUTENZIONE	CHIAVE	ADATTATORE DI CARICO
ESP PEDIDO	RESORTE DE GAS	KIT DE REPARACION	LLAVE	ADAPTADOR DE CARGA
POR PEDIDO	CILINDRO DE GÁS	KIT DE MANUTENÇÃO	CHAVE	ADAPTADOR DE CARGA