


5522	BRIDE DE FIXATION CLAMP
REF. 5522 Type=4 → 5522-4	

NF E 63-125
ISO 9448

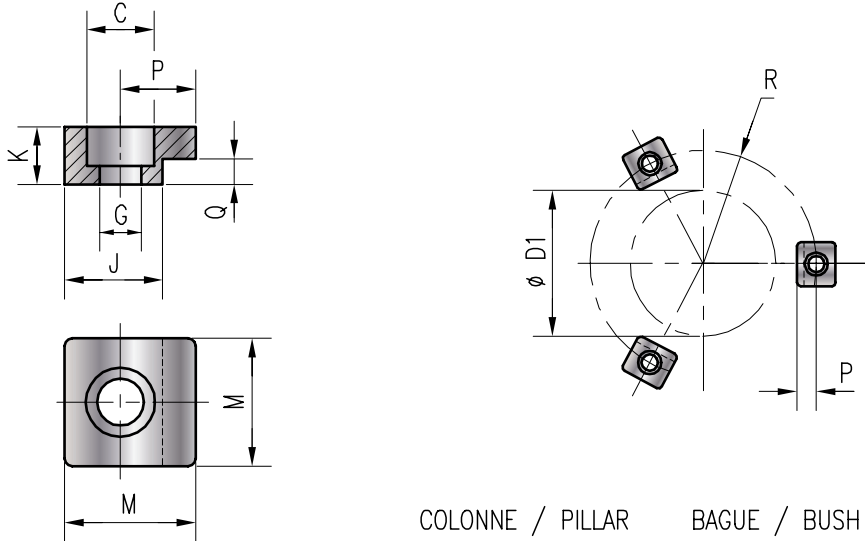

COLONNE / PILLAR BAGUE / BUSH

C	8	9	12	16	18
G	4,5	5,5	6,6	9	11
J	10,5	12	15,5	19	21
K	5	7	9	11	18
M	12	14	18	22	26
P	6	7	9,5	12	15
Q	2,75	3,75	4,75	5,75	9,75
vis 527	M4 x 10	M5 x 12	M6 x 16	M8 x 20	M10 x 20
Type	1	2	3	4	5
REF. 5522					

brides pour les bagues SINT-ER / clamps for SINT-ER bushes : REF. 5385-5386-5387-5388-5389													
D1	-	19	20	24	25	30	32	38	40	48	50	63	80
R	-	21,75		29		34,5		39		47		57	68
Nb	-	2		2		3		4		4		4	
Type		1		2		3							

brides pour les bagues SINT-GR, "BRONZACIER", "LUBRACIER" / clamps for SINT-GR, BRONZE LINED STEEL and "LUBSTEEL" bushes : REF. 5347-5348-5349-5357-5358-5359-5367-5368-5736-5737-5738														
D1	12	16	19	20	24	25	30	32	38	40	48	50	63	80
R	17,5	21	23,5		28		35	35,5	42,5		54,5		65,5	78,5
Nb	2			2					3		3		4	
Type	1			2					3		4		5	

brides pour la colonne / clamps for pillar : REF. 5432													
D1	-	19	20	24	25	30	32	38	40	48	50	63	80
R	-	18,5		21,5		27,5		32,5		41		48,5	55,5
Nb	-		3			3		4		4		4	
Type			2					3		4			5