


Round cable entry gland plate, CEPR

- Description:** Round plastic cable entry for a fast, economical and tool-free incoming of cables and/or pneumatic conduits inside the enclosure. Integrated seal. For snap-in mounting. Snap-in system works at wall thicknesses of 1.4 to 2 mm. Installation height: 9 mm outside, and 24-25 inside.
- Material:** Polyamide, and the seal is made of NBR/EPDM, halogen free.
- Temperature resistance:** -30°C to +90°C.
- Flammability:** V-0 according to UL94.
- Finish:** Black.
- Protection:** IP 65.
- Pack quantity:** 1 piece.




H1	H2	Diameter	Hole diameter (mm)	Openings (mm)			Item no.
				3-5	3 - 6,5	6-10	
9	24	58	50.5	-	7	1	CEPR5008
9	25	71	63.5	19	-	-	CEPR6319

Front view

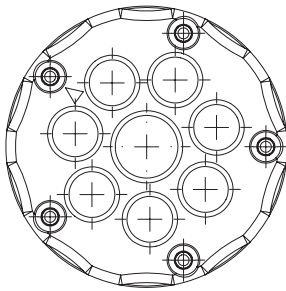

Side view

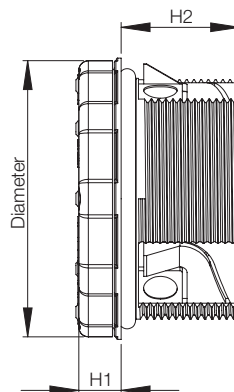

Cut-out

