

Terminal Boxes

Polycarbonate Range

Polycarbonate terminal box | DPCP

IP 66,67 | IK 08



Description:

Polycarbonate box, halogen-free, suitable for outdoor use. High UV radiation resistance. Self-extinguising.

Material:

Polycarbonate.

Gasket:

Polyurethane gasket integrated in the box cover.

Temperature resistance:

-40°C to +80°C.

Flammability:

UL746C 5V.

Protection:

IP 66, 67 | IK 08 (-25°C...+35°C).

Finish:

RAL 7035.

Approvals:

CE, GOST. For cULus_UL Listed approvals, please contact our sales department.

Delivery:

Body, cover, cover screws made of stainless steel, mounting screws and cover plugs made of polyamide.

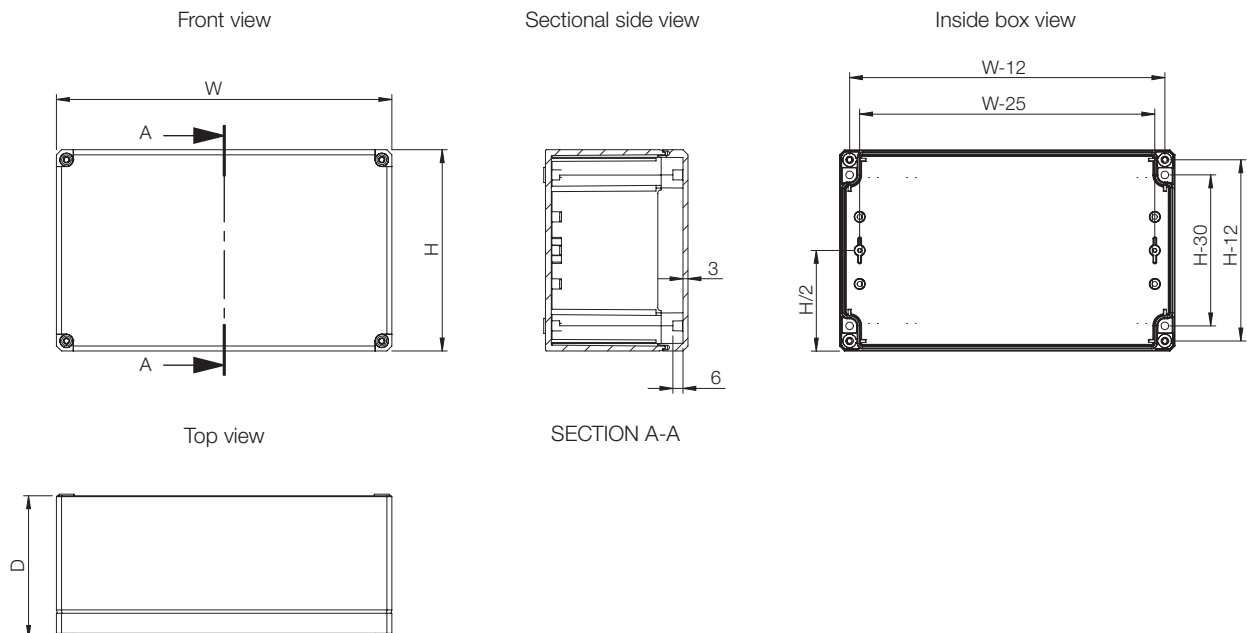


IP 66,67 | IK 08





Box dimension				
H	W	D	Inner depth (mm)	Item no.
53	55	36	27.5	DPCP050504GE
53	65	36	25	DPCP050704GE
80	82	56	42	DPCP080806GE
80	82	86	72	DPCP080809GE
80	120	56	42	DPCP081206GE
80	120	86	72	DPCP081209GE
80	160	56	42	DPCP081606GE
80	160	86	72	DPCP081609GE
120	122	56	42	DPCP121206GE
120	122	86	72	DPCP121209GE
120	160	91	77.5	DPCP121609GE
120	200	86	72	DPCP122009GE
150	200	76	62	DPCP152008GE
160	240	91	77.5	DPCP162409GE
160	240	121	107.5	DPCP162412GE
230	300	86	72.5	DPCP233009GE
230	300	111	97.5	DPCP233011GE

Note: Terminal box with transparent cover fitted can be ordered by replacing GE with TE in the item number.

Dimensional drawing | DPCP



Accessories selection matrix | DPCP

							
Box				Mounting		Fixing	Cover
	H	W	D	Mounting plate	DIN rail	Wall mounting brackets	Hinges
DPCP050504GE	53	55	36	-	-	DFL1E	DSH1E
DPCP050704GE	53	65	36	-	-	DFL1E	DSH1E
DPCP080806GE	80	82	56	DMP0808E	DR350584E	DFL1E	DSH1E
DPCP080809GE	80	82	86	DMP0808E	DR350584E	DFL1E	DSH1E
DPCP081206GE	80	120	56	DMP0812E	DR350964E	DFL1E	DSH1E
DPCP081209GE	80	120	86	DMP0812E	DR350964E	DFL1E	DSH1E
DPCP081606GE	80	160	56	DMP0816E	DR351364E	DFL1E	DSH1E
DPCP081609GE	80	160	86	DMP0816E	DR351364E	DFL1E	DSH1E
DPCP121206GE	120	122	56	DMP1212E	DR350964E	DFL1E	DSH1E
DPCP121209GE	120	122	86	DMP1212E	DR350964E	DFL1E	DSH1E
DPCP121609GE	120	160	91	DMP1216E	DR351364E	DFL1E	DSH1E
DPCP122009GE	120	200	86	DMP1220E	DR351764E	DFL1E	DSH1E
DPCP152008GE	150	200	76	DMP1520E	DR351604E	DFL1E	DSH1E
DPCP162409GE	160	240	91	DMP1624E	DR352154E	DFL1E	DSH1E
DPCP162412GE	160	240	121	DMP1624E	DR352154E	DFL1E	DSH1E
DPCP233009GE	230	300	86	DMP2330E	DR352754E	DFL1E	DSH1E
DPCP233011GE	230	300	111	DMP2330E	DR352754E	DFL1E	DSH1E