

Terminal Boxes

Polyester Range

Polyester terminal box | MGRP

IP 66, 67



Material:

Glass fibre reinforced polyester.

Gasket:

Standard supply fitted with a polyurethane gasket.
Silicone, neoprene and EPDM gaskets are available on request.

Temperature resistance:

-40°C to +100°C with the standard polyurethane gasket; -60°C to +130°C with the silicone gasket; -35°C to +100°C with the EPDM gasket; -30°C to +80°C with the neoprene gasket.

Flammability:

UL94 V-0.

Protection:

IP 66, 67.

Finish:

RAL 7000.

Approvals:

CE, GOST. For cULus_UL Listed approvals, please contact our sales department.

Delivery:

Body, cover and cover screws made of stainless steel.




IP 66, 67

Box dimension			Item no.
H	W	D	
75	80	55	MGRP080806GE
75	80	75	MGRP080808GE
75	110	55	MGRP081106GE
75	110	75	MGRP081108GE
75	160	55	MGRP081606GE
75	160	75	MGRP081608GE
75	190	55	MGRP081906GE
75	190	75	MGRP081908GE
120	122	90	MGRP121209GE
120	220	90	MGRP122209GE
160	160	90	MGRP161609GE
160	260	90	MGRP162609GE
160	360	90	MGRP163609GE
160	560	90	MGRP165609GE
250	255	120	MGRP252612GE
250	400	120	MGRP254012GE
405	400	120	MGRP414012GE



Dimensional drawing | MGRP

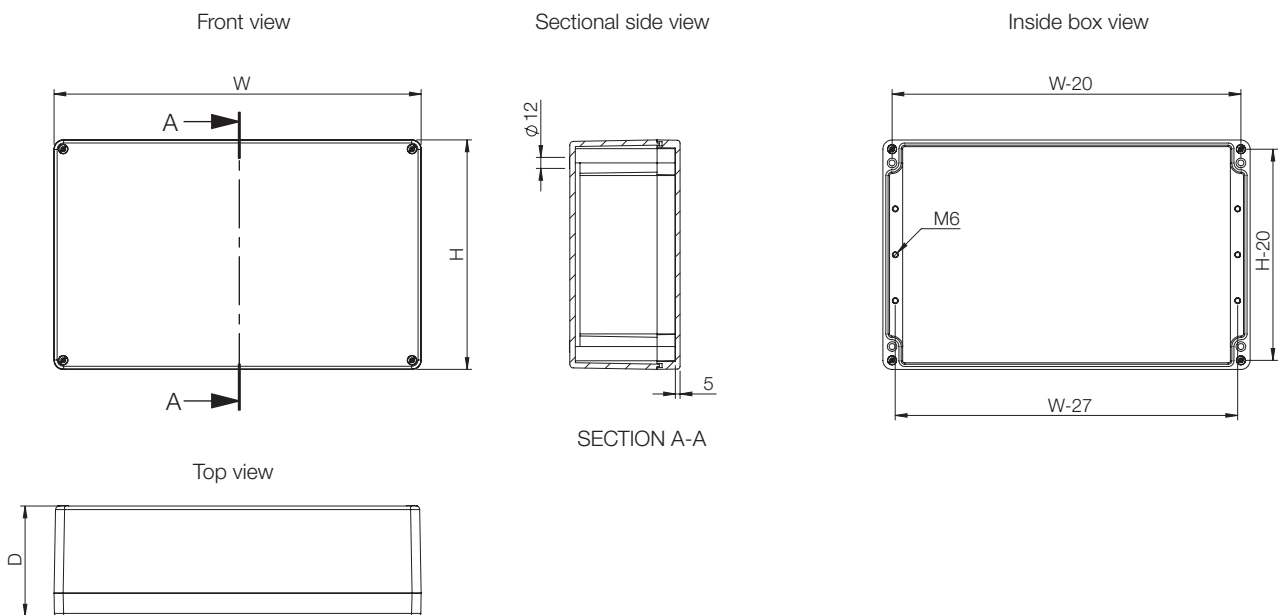

Terminal Boxes

Polyester Range

Accessories


MGRP Mounting plate, GMP

Description: Mounting plate for MGRP boxes.

Material: 1.5 mm galvanized steel, 2.5 mm for GMP1656E.

Pack quantity: 1 piece.

For box		Mounting plate dimensions		Item no.
H	W	h	w	
75	80	64	69	GMP0808E
75	110	64	99	GMP0811E
75	160	64	149	GMP0816E
75	190	64	179	GMP0819E
120	122	107	108	GMP1212E
120	220	107	206	GMP1222E
160	160	144	143	GMP1616E
160	260	144	244	GMP1626E
160	360	144	344	GMP1636E
160	560	144	544	GMP1656E
250	255	233	240	GMP2526E
250	400	233	383	GMP2540E
405	400	390	385	GMP4140E

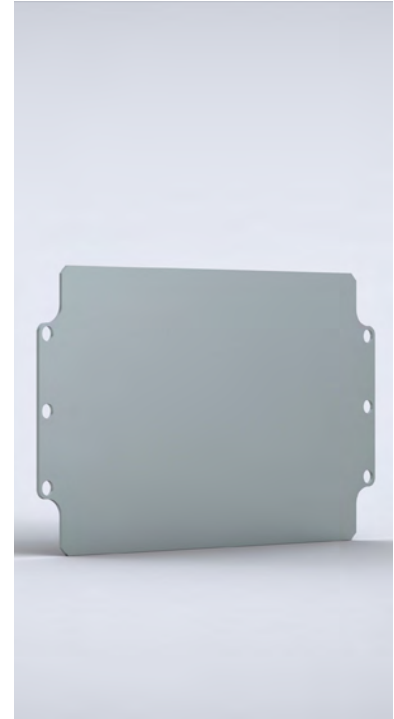

Hinges, HHI

Description: Using this accessory the cover can be hinged. 150° Openingshoek. Machinale is required.

Material: Aluminium.

For box: HHI03: MGRP121209GE to MGRP414012GE.

Pack quantity: Set of 3 hinges. Mounting accessories are included.

Item no.
HHI03

