

## Końcówka złącza z zaworem

Fitting with valve



# CD18

NPT – gwint według norm amerykańskich – kąt zarysu 60°

BSPT – gwint według norm brytyjskich – kąt zarysu 55°

NPT – US Standard – profile of thread 60°

BSPT – British Standard – profile of thread 55°

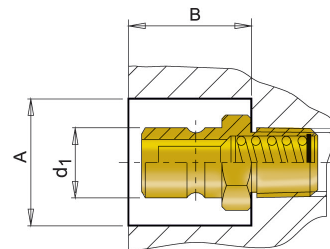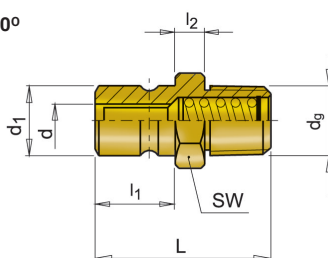


NR KAT. BSPT	d <sub>g</sub>	d	d <sub>1</sub>	l <sub>1</sub>	l <sub>2</sub>	L	SW	A	B
CD18-9-1/4-B	1/4"	6	9	10,5	4	29	14	21	20
CD18-9-3/8-B	3/8"						17	24	
CD18-13-1/4-B	1/4"	9	13	15,5	5	33	14	27	26
CD18-13-3/8-B	3/8"						17		
CD18-13-1/2-B	1/2"				5,5	37	22	34	
NR KAT. NPT	d <sub>g</sub>	d	d <sub>1</sub>	l <sub>1</sub>	l <sub>2</sub>	L	SW	A	B
CD18-9-1/4-N	1/4"	6	9	10,5	4	29	14	21	20
CD18-9-3/8-N	3/8"						17	24	
CD18-13-1/4-N	1/4"	9	13	15,5	5	33	14	27	26
CD18-13-3/8-N	3/8"						17		
CD18-13-1/2-N	1/2"				5,5	37	22	34	
NR KAT.	d <sub>g</sub>	d	d <sub>1</sub>	l <sub>1</sub>	l <sub>2</sub>	L	SW	A	B
CD18-9-14-M	M14x1,5	6	9	10,5	4,5	29	14	21	20
CD18-13-14-M	M14x1,5	9	13	15,5	5,5	34		27	26

## Końcówka złącza kątowna 90°

Fitting 90°

# CD19

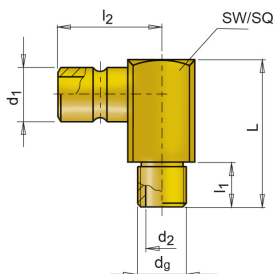

NR KAT.	d <sub>g</sub>	d <sub>1</sub>	d <sub>2</sub>	l <sub>1</sub>	l <sub>2</sub>	L	SW/SQ
CD19-9-1/8	R 1/8"	9	6	9	23	27	11
CD19-9-10	M10x1			9	23	27	11
CD19-9-1/4	R 1/4"			12	24	34	15
CD19-9-14	M 14x1,5			12	24	34	15
CD19-9-3/8	R 3/8"			12	24	34	17
CD19-13-1/4	R 1/4"	13	9	12	24	34	15
CD19-13-3/8	R 3/8"			12	24	34	17