


Sprężyny poliuretanowe
Polyurethane springs

Typ **SU-M**
Type

Przykład zamawiania:
Example order:

SU-M050080
90 ShoreA
D= 50mm
L = 80mm

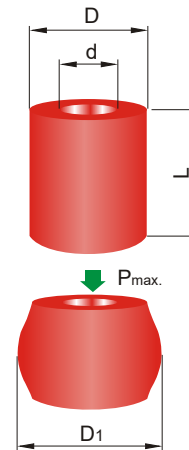

Średnica Diameter D [mm]	Max. obciążenie Max. Load [N]	d [mm]	D1 [mm]	90 Shore A												
				L [mm]												
				12	16	20	25	32	40	50	63	80	100	125	160	
Obciążenie [N] na każdy mm ugięcia Load [N] for each mm of compression																
16	1100	6,5	21,3	300	230	180	150									
20	2200	8,5	26,6		460	360	290	230								
25	3300	10,5	33,3			550	440	340	270							
32	5000	13,5	42,6					520	410	330	260					
40	9800	13,5	53,2					1030	810	650	515	408				
50	17500	18,0	66,5					1825	1450	1160	920	730	580			
63	28300	18,0	83,8					2950	2350	1880	1490	1180	940	755		
80	42500	21,0	106,4					4225	3530	2820	2230	1770	1410	1130		
100	70500	21,0	133,0					7325	5850	4700	3700	2930	2350	1880		
125	85200	27,0	166,3					8875	7100	5680	4490	3550	2840	2270	1770	
Max. ugięcie [mm] Max. compression [mm]			30%	3,6	4,8	6,0	7,5	9,5	12,0	15,0	19,0	24,0	30,0	37,0	48,0	