


ÇEKTİRME CİVATASI, DIN 9825/ISO 9182-4


ÇEKTİRME CİVATASI, ~AFNOR

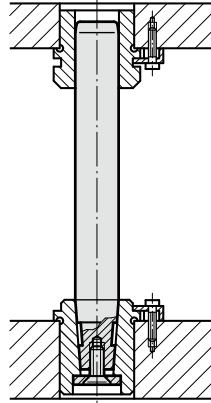

Montaj Örneği



2021.53.

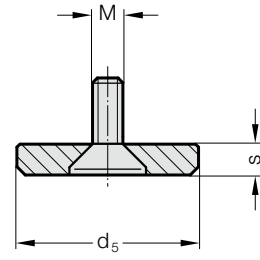

Malzeme:

Çektirme civatası: Çelik, açkılı
Civata DIN 7991/ISO 10642

Not:


Sökülebilir kolonlar, konik DIN 9825/ISO 9182-4 2021.50. ya da 2021.58. ek olarak sipariş edilmelidir.

2021.53. Çektirme civatası, DIN 9825/ISO 9182-4


Sipariş No.	Nominal-ø	Kolon ø	d ₅	s	M
2021.53.020	20	19/20	22	3	M6
2021.53.025	25	24/25	25	3	M8
2021.53.032	32	30/32	32	3	M8
2021.53.040	40	38/40	40	5	M8
2021.53.050	50	48/50	50	5	M10
2021.53.063	63	60/63	63	6	M12



Montaj Örneği

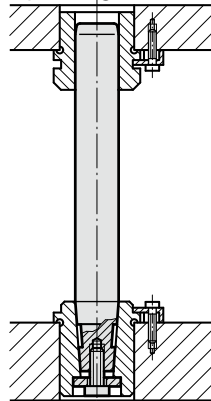

202.53.

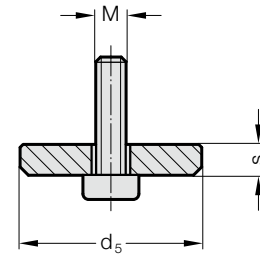

Malzeme:

Çektirme civatası: Çelik, açkılı
Civata DIN 6912

Not:

Sökülebilir kolonlar, konik AFNOR 2021.50. ya da 2021.58. ek olarak sipariş edilmelidir.

202.53. Çektirme civatası, ~AFNOR

Sipariş No.	Kolon ø	d ₅	s	M
202.53.016	16	18	3	M6
202.53.020	20	22	3	M6
202.53.025	25	25	4	M8
202.53.032	32	32	4	M8
202.53.040	40	40	4	M8
202.53.050	50	50	5	M10
202.53.063	63	63	6	M12