


带肩导套，带固态润滑剂的青铜

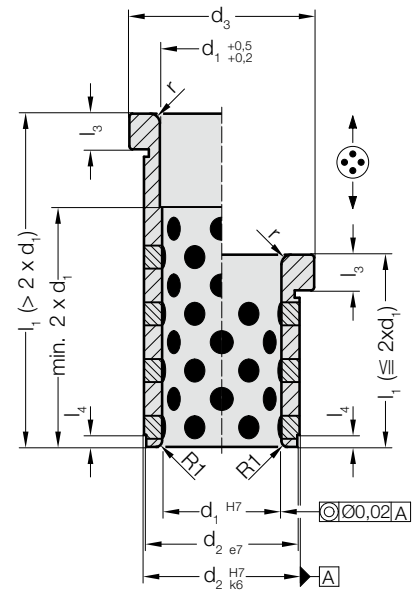

2087.72.



材料:

带固态润滑剂的铜，易维护

说明:

☞ 安装说明/尺寸及公差要求见D章最后。

注意:

该导套只能在轴向运动上使用。

2087.72. 带肩导套，带固态润滑剂的青铜

d ₁	9 10	12	14 15	16	18 20	22 24	25	30 32	40 42	50	60
d ₂	14	18	20	22	26	30	32	42	54	66	80
d ₃	16	23	25	27	31	35	38	47	60	72	86
r	0.5	1	1	2	2	3	3	3	3	3	3
l ₃	3	6	6	6	6	6	6	6	10	10	20
l ₄	1.5	2	2	2	2	3	3	4	5	5	5
l ₁	●										
12	●										
17	●	●	●	●	●	●	●				
22	●	●	●	●	●	●	●				
27	●	●	●	●	●	●	●				
36	●	●	●	●	●	●	●	●			
46	●	●	●	●	●	●	●	●	●		
56	●	●	●	●	●	●	●	●	●	●	●
66	●										
76	●										
86	●										
96	●										
116	●										
136	●										
156	●										
196	●										

订购示例:

带肩导套，带固态润滑剂的青铜	= 2087.72.
导向装置直径 d ₁	22 mm = 022.
总长度 l ₁	17 mm = 017
订购编号	= 2087.72.022.017