


CİVATALAR

SOMUN DIN 6330 B

2140.02.

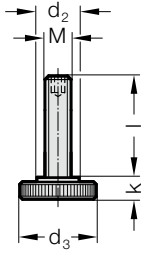


2140.02. Civatalar

Sipariş No.	M	d ₂	d ₃	k	l
2140.02.10	10	16	30	8	39
2140.02.12	12	20	36	10	48
2140.02.16	16	25	42	13	55
2140.02.20	20	25	50	16	69
2140.02.24	24	34	60	20	87

Malzeme:

Isıl işlem görmüş 8.8 kalite

2140.32.

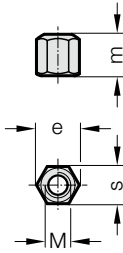

2140.32. Somun DIN 6330 B

Sipariş No.	M	e	m	s
2140.32.08	M8	15	12	13
2140.32.10	M10	18,4	15	16
2140.32.12	M12	20,7	18	18
2140.32.14	M14	24,2	21	21
2140.32.16	M16	27,7	24	24
2140.32.18	M18	31,2	27	27
2140.32.20	M20	34,6	30	30
2140.32.22	M22	39,2	33	34
2140.32.24	M24	41,5	36	36
2140.32.30	M30	53,1	45	46

Malzeme:

Isıl işlem görmüş 10.9 kalite

Not:

DIN 6340'e uyumlu vidalar kullanınız.