


圆柱销 类似于 DIN EN ISO 8734

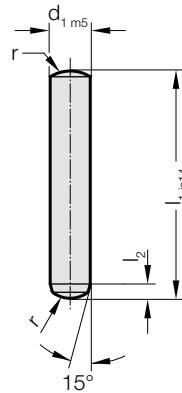

235.1.



材料:

钢

硬度 60 ± 2 HRC

结构:

淬火处理,精磨。

FIBRO - 精密圆柱销, 其结构形式 适合精密模具制造独特的. 按标准
DIN EN ISO 8734 允许直径 公差为 m6, 我公司将允许直径公差压缩到 m5。

235.1. 圆柱销 类似于 DIN EN ISO 8734

d_1	l_2	r	l_1	6	8	10	12	14	16	18	20	24	28	32	36	40	45	50	55	60	70	80	90	100	120	130	140
1	0.48	1		●		●		●		●																	
1.5	0.62	1.6		●	●	●	●	●	●	●																	
2	0.78	2		●	●	●	●	●	●	●																	
2.5	0.95	2.5		●	●	●	●	●	●	●																	
3	1.1	3		●	●	●	●	●	●	●																	
4	1.4	4		●	●	●	●	●	●	●																	
5	1.7	5		●	●	●	●	●	●	●																	
6	2.1	6		●	●	●	●	●	●	●																	
8	2.6	8		●	●	●	●	●	●	●																	
10	3	10				●	●	●	●	●																	
12	3.8	12				●	●	●	●	●																	
14	3.8	16									●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	
16	4.7	16									●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	
20	6	20														●	●	●	●	●	●	●	●	●	●	●	●

订购示例:

圆柱销 类似于 DIN EN ISO 8734 = 235.1.

直径 d_1 6 mm = 0600.

长度 l_1 10 mm = 010

订购编号 = 235.1.0600. 010