


垫圈


244.10.

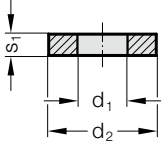

244.10. 垫圈

| 订购编号 | d_1 | d_2 | s_1 | 订购编号 | d_1 | d_2 | s_1 |
|-------------------|-------|-------|-------|-------------------|-------|-------|-------|
| 244.10.064.017.03 | 6.4 | 17 | 3 | 244.10.204.030.05 | 20.4 | 30 | 5 |
| 244.10.084.016.04 | 8.4 | 16 | 4 | 244.10.210.042.06 | 21 | 42 | 6 |
| 244.10.084.017.03 | 8.4 | 17 | 3 | 244.10.210.042.08 | 21 | 42 | 8 |
| 244.10.084.023.04 | 8.4 | 23 | 4 | 244.10.210.044.08 | 21 | 44 | 8 |
| 244.10.085.020.04 | 8.5 | 20 | 4 | 244.10.210.045.08 | 21 | 45 | 8 |
| 244.10.090.026.04 | 9 | 26 | 4 | 244.10.210.045.16 | 21 | 45 | 16 |
| 244.10.105.020.04 | 10.5 | 20 | 4 | 244.10.210.046.06 | 21 | 46 | 6 |
| 244.10.105.025.04 | 10.5 | 25 | 4 | 244.10.210.049.06 | 21 | 49 | 6 |
| 244.10.105.025.05 | 10.5 | 25 | 5 | 244.10.210.050.10 | 21 | 50 | 10 |
| 244.10.105.026.04 | 10.5 | 26 | 4 | 244.10.210.065.08 | 21 | 65 | 8 |
| 244.10.105.028.04 | 10.5 | 28 | 4 | 244.10.210.070.12 | 21 | 70 | 12 |
| 244.10.105.030.05 | 10.5 | 30 | 5 | 244.10.220.065.12 | 22 | 65 | 12 |
| 244.10.110.030.06 | 11 | 30 | 6 | 244.10.220.068.12 | 22 | 68 | 12 |
| 244.10.110.036.06 | 11 | 36 | 6 | 244.10.230.038.07 | 23 | 38 | 7.5 |
| 244.10.125.028.04 | 12.5 | 28 | 4 | 244.10.250.042.09 | 25 | 42 | 9 |
| 244.10.130.024.05 | 13 | 24 | 5.5 | 244.10.250.046.10 | 25 | 46 | 10 |
| 244.10.130.030.05 | 13 | 30 | 5 | 244.10.250.055.10 | 25 | 55 | 10 |
| 244.10.130.035.05 | 13 | 35 | 5 | 244.10.250.056.10 | 25 | 56 | 10 |
| 244.10.130.030.06 | 13 | 30 | 6 | 244.10.250.065.12 | 25 | 65 | 12 |
| 244.10.130.035.08 | 13 | 35 | 8 | 244.10.250.070.10 | 25 | 70 | 10 |
| 244.10.130.046.08 | 13 | 46 | 8 | 244.10.250.090.12 | 25 | 90 | 12 |
| 244.10.134.023.04 | 13.4 | 23 | 4 | 244.10.260.058.06 | 26 | 58 | 6 |
| 244.10.135.026.05 | 13.5 | 26 | 5 | 244.10.260.070.12 | 26 | 70 | 12 |
| 244.10.164.026.04 | 16.4 | 26 | 4 | 244.10.260.080.12 | 26 | 80 | 12 |
| 244.10.170.030.06 | 17 | 30 | 6 | 244.10.290.050.08 | 29 | 50 | 8 |
| 244.10.170.034.06 | 17 | 34 | 6 | 244.10.310.068.08 | 31 | 68 | 8 |
| 244.10.170.035.04 | 17 | 35 | 4 | 244.10.310.068.10 | 31 | 68 | 10 |
| 244.10.170.035.06 | 17 | 35 | 6 | 244.10.310.080.12 | 31 | 80 | 12 |
| 244.10.170.036.04 | 17 | 36 | 4 | 244.10.310.100.15 | 31 | 100 | 15 |
| 244.10.170.036.13 | 17 | 36 | 13 | 244.10.320.090.15 | 32 | 90 | 15 |
| 244.10.170.037.06 | 17 | 37 | 6 | 244.10.320.092.15 | 32 | 92 | 15 |
| 244.10.170.038.06 | 17 | 38 | 6 | 244.10.370.060.08 | 37 | 60 | 8 |
| 244.10.170.040.06 | 17 | 40 | 6 | 244.10.370.080.08 | 37 | 80 | 8 |
| 244.10.170.050.06 | 17 | 50 | 6 | 244.10.430.092.08 | 43 | 92 | 8 |
| 244.10.170.050.10 | 17 | 50 | 10 | | | | |
| 244.10.170.058.10 | 17 | 58 | 10 | | | | |

安装示例

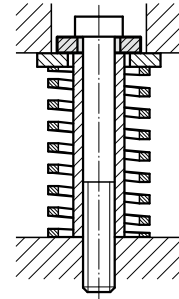

材料:
C 45 调质处理