



DISTANZROHR

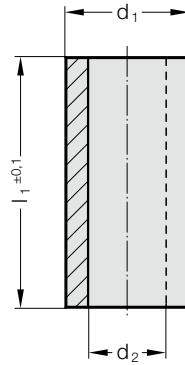

244.9.



Einbaubeispiel

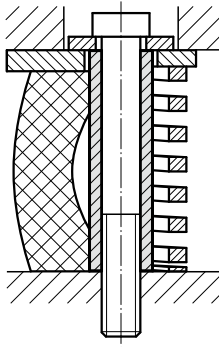

Werkstoff:

E235 (1.0308), carbonitriert

Hinweis:

Andere Längen auf Anfrage!

244.9. Distanzrohr

d ₁	10	12	13	16	19	20	25	30	32	35	36	36	42	42	55
d ₂	6,4	8,4	9	11	13	13	17	22	22	23	22	26	26	32	31
l ₁															
27	•	•													
30			•	•	•										
33	•	•		•		•									
38	•	•		•		•									
40			•		•										
44	•	•		•		•									
48	•	•		•		•	•								
50			•		•		•	•				•			
61	•	•		•		•	•	•				•			
63		•	•	•	•	•	•	•				•			
70							•	•							
72	•	•		•		•	•	•		•			•		
80	•	•	•	•	•	•	•	•		•	•	•	•	•	
90		•		•		•	•	•		•		•			
95							•	•							
100		•	•	•	•	•	•	•		•	•	•	•		
105							•	•		•					
115							•	•							
125				•	•	•	•	•	•	•	•	•	•	•	
135							•	•							
145								•		•					
150				•		•	•	•		•	•	•	•	•	•
155							•	•							
165								•		•					
175							•	•		•		•			
185								•		•					
195							•	•		•					
200			•		•	•	•	•		•	•	•	•	•	•
205								•							
215							•	•							
225							•	•	•	•		•			
235							•	•				•			
245								•		•					
250							•	•		•		•			
255							•	•							

Bestell-Beispiel:

Distanzrohr	=	244.9.
Innendurchmesser d ₂	6,4 mm	064.
Außendurchmesser d ₁	10 mm	10.
Länge l ₁	27 mm	027
Bestell-Nummer	=	244.9. 064. 10. 027