



TUBO DISTANZIATORE

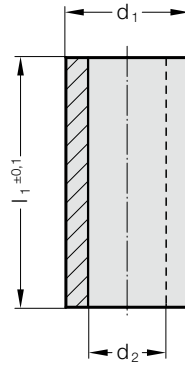

244.9.



Esempio di montaggio

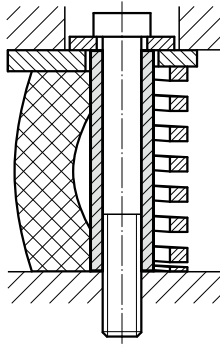

Materiale:

E235 (1.0308), carbonitrurato

Nota:

Altre lunghezze a richiesta!

244.9. Tubo distanziatore

d ₁	10	12	13	16	19	20	25	30	32	35	36	36	42	42	55
d ₂	6,4	8,4	9	11	13	13	17	22	22	23	22	26	26	32	31
l ₁															
27	•	•													
30															
33	•	•		•	•										
38	•	•		•	•										
40				•	•										
44	•	•		•	•										
48	•	•		•	•										
50				•	•										
61	•	•		•	•							•			
63		•	•	•	•							•			
70															
72	•	•		•	•								•	•	
80	•	•	•	•	•							•	•	•	•
90		•		•	•							•	•	•	
95															
100		•	•	•	•							•	•	•	•
105															
115															
125				•	•	•						•	•	•	•
135															
145															
150				•		•						•	•	•	•
155															
165															
175															
185															
195															
200				•		•						•	•	•	•
205															
215															
225															
235															
245															
250															
255															

Esempio di ordinazione:

Tubo distanziatore	=	244.9.
Diametro interno d ₂	6,4 mm	064.
Diametro esterno d ₁	10 mm	10.
Lunghezza l ₁	27 mm	027
N. d'ordine	=	244.9. 064. 10. 027