


气压弹簧-附件

转位式组合供气系统的螺栓连接

2480.00.10.20.12.01

 
的软管夹
测量软管 DN4 (Ø 9 mm)

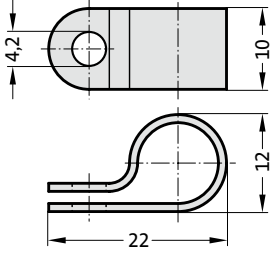

材料:
聚酰胺
说明:
供货范围内不包含螺栓



2192.50.04.012
自攻螺钉 DIN 7516
M4x12



说明:
自攻型
螺纹芯孔 Ø = 3.6 mm



2480.00.23.13.

清洗保护螺旋管
用于随后安装到软管上



订购号	l [m]
2480.00.23.13.0001	1
2480.00.23.13.0002	2
2480.00.23.13.0005	5
2480.00.23.13.0010	10

内径 Ø 7 mm
用于软管外径 Ø 最大 5-11 mm
-30°C 至 +100°C


描述:
这种清洗保护螺旋管用于防磨损, 它对空气、水、油、液压油、汽油和其它介质的腐蚀不敏感。

材料:
聚酰胺




2480.00.54.01

软管扩孔芯轴

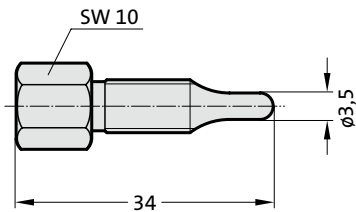

2480.00.10.20.

高压软管

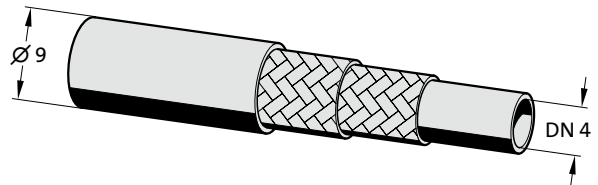


订购示例:

高压软管	= 2480.00.10.20.
长度 10 m	= 0010
订购号	= 2480.00.10.20.0010




2480.00.54.02

副钳口
用于夹紧软管

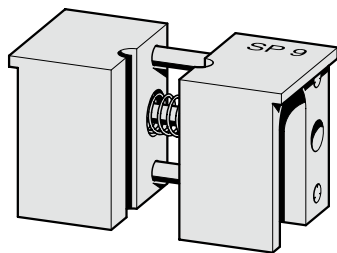


2480.00.10.21

软管搭扣

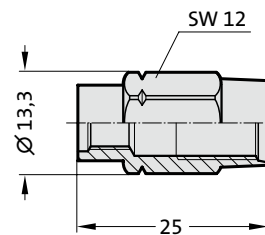

2480.00.54.03

软管剪

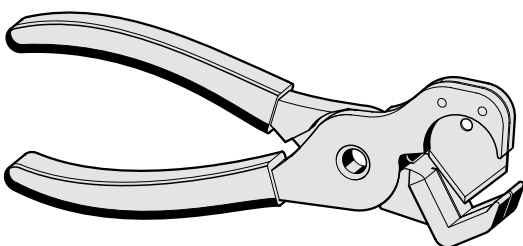

2480.00.10.22

软管接头

