


气压弹簧-附件

24° 微型椎体的管

2480.00.27.11


最小弯曲半径 R12 mm (3x 外径)

24°微型椎体的管
供货长度: 1 m

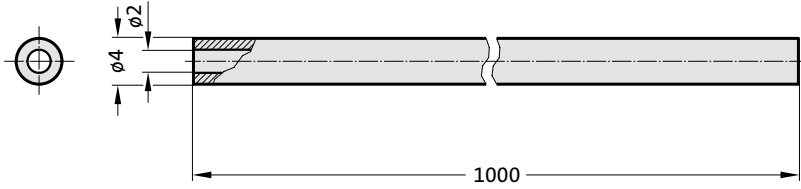


2480.00.27.11.01

切割环螺钉连接 - 管24°微型椎体

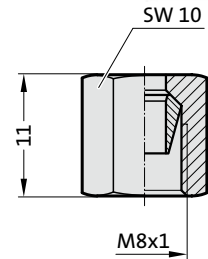


2480.00.27.00.01

24°微型椎体管的去毛刺工具

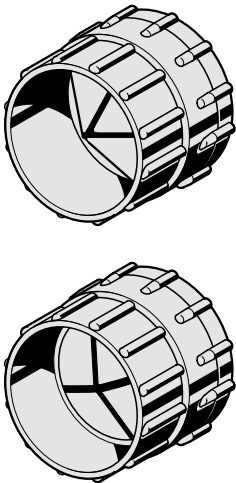

2480.00.27.00.02

24°微型椎体管的管切割机

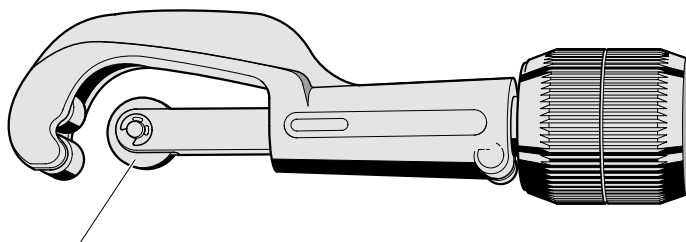

2480.00.27.00.02.1

管道切割机的备用切割轮