


# 顶针, 有硬度 , 类似于DIN ISO 8693

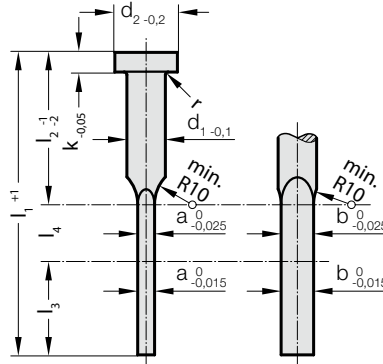

263.1.



**材料:**

WS  
 订购编号 263.1.  
 硬度:  
 杆部 60 ± 2 HRC  
 头部 45 ± 5 HRC

☞ 材料说明和其他材料见E章开头。

**结构:**

经精磨、淬火处理的轴。  
 热顶锻的头。

**说明:**

也可以根据需要供应特殊规格 a 和 b。

263.1. 顶针, 有硬度 , 类似于DIN ISO 8693

d <sub>1</sub>	4	4.2	4.2	4.2	5	5	5	6	6	6	6	8	8	8	10	10	12	12
d <sub>2</sub>	8	8	8	8	10	10	10	12	12	12	12	14	14	14	16	16	18	18
k	3	3	3	3	3	3	3	5	5	5	5	5	5	5	5	5	7	7
r	0.3	0.3	0.3	0.3	0.3	0.3	0.3	0.5	0.5	0.5	0.5	0.5	0.5	0.5	0.5	0.5	0.8	0.8
a	1	1	0.8	1.2	1	1.2	1.5	1	2	1.5	1.2	1.2	1.5	2	1.5	2	2	2.5
b	3.5	3.8	3.8	3.8	4.5	4.5	4.5	5.5	5.5	5.5	5.5	7.5	7.5	7.5	9.5	9.5	11.5	11.5
l <sub>1</sub>	63	30	25	10														
l <sub>2</sub>	80	40	30	10														
l <sub>3</sub>	100	50	40	10														
l <sub>4</sub>	125	60	50	15														
	160	80	50	30														
	200	100	60	40														
	250	125	60	65														
	315	160	70	85														

**订购示例:**

顶针, 有硬度, 类似于DIN ISO 8693	=263.1.
宽 a	1.5 mm = 15.
长度 b	5.5 mm = 055.
长度 l <sub>1</sub>	100 mm = 100
订购编号	=263.1. 15.055.100