


VRTACÍ POUZDRO BEZ NÁKRUŽKU, DIN 179 TVAR A

277.

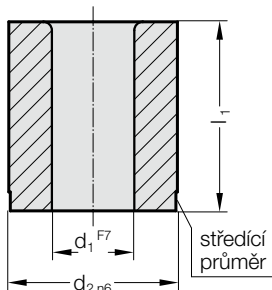

Materiál:

ocel k cementování
Tvrdost 740 ± 40 HV 10

Provedení:

Průměr d_1 a d_2 broušený.

Jiné délky a průměry na poptávku.

277. Vrtací pouzdro bez nákrůžku, DIN 179 tvar A

d_1	d_2	Odstupňování	l_1	6	8	9	10	12	16	20	25	28	30	36	45	56	67
0,9 - 1	3	0.1		●		●											
1,1 - 1,8	4	0.1		●		●											
1,9 - 2,6	5	0.1		●		●											
2,7 - 3,3	6	0.1			●			●	●								
3,4 - 4	7	0.1			●			●	●								
4,1 - 5	8	0.1			●			●	●								
5,1 - 6	10	0.1					●		●								
6,1 - 8	12	0.1					●		●	●							
8,1 - 10	15	0.1						●	●	●							
10,1 - 12	18	0.1						●	●	●							
12,1 - 15	22	0.1							●	●			●	●			
15,5 - 18	26	0.5							●			●		●			
18,5 - 22	30	0.5								●				●	●		
22,5 - 26	35	0.5								●				●	●		
26,5 - 30	42	0.5									●			●	●	●	
30,5 - 35	48	0.5									●			●	●	●	
35,5 - 42	55	0.5										●		●	●	●	●
42,5 - 48	62	0.5											●	●	●	●	●

Příklad objednávky:

Vrtací pouzdro bez nákrůžku, DIN 179 tvar A = 277.1.
 Průměr vedení d_1 12.1 mm = 1210.
 Délka l_1 16 mm = 016
 Objednávací číslo = 277.1. 1210.016