


GUIDE BUSH, BRONZE



3120.71.

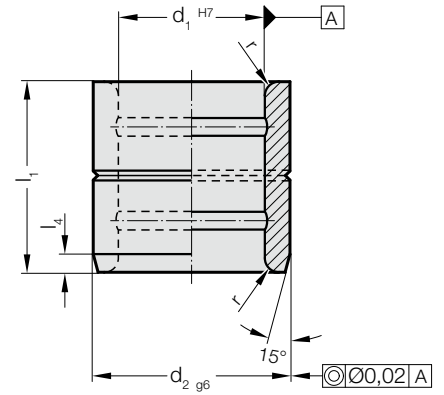

Material:

Bronze

Note:

Bushes can be used with radial or axial motion.

Assembly guide lines / Dimensional requirements and tolerances at the end of chapter D.

Fixing:

Connecting with adhesive or if needed secure with threaded pin or flat mushroom head screw 2192.61.

3120.71. Guide bush, Bronze


d ₁	8	10	10	12	13	14	15	16	18	20	20	20	24	25	25	25	28	30	30	30	31.5	32	35	35	38	40	40
d ₂	12	14	15	18	19	20	21	22	24	26	28	30	32	32	33	35	38	38	40	42	40	42	44	45	48	50	55
r	0.5	0.5	0.5	0.5	0.5	0.5	0.75	0.75	0.75	0.75	0.75	0.75	0.75	0.75	0.75	0.75	0.75	0.75	0.75	0.75	0.75	0.75	0.75	0.75	1.5	1.5	1.5
l ₄	2	2	2	2	2	2	2	2	2	4	4	4	4	4	4	4	4	4	4	4	4	4	4	4	4	4	4
l ₁																											
8	●	●																									
10	●	●	●	●	●	●	●	●																			
12	●	●		●	●	●	●	●																			
15	●	●		●	●	●	●	●	●																		
16				●	●	●	●	●	●	●	●	●	●	●	●	●											
20		●		●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
25				●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
30				●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
35																											
37																											
40																											
47																											
50																											
60																											
70																											
77																											
80																											

Ordering Code (example):

Guide bush, Bronze	=3120.71.
Diameter of conduit d ₁	40 mm = 040.
Outer diameter d ₂	55 mm = 055.
Installation length l ₁	25 mm = 025
Order No	=3120.71. 040. 055. 025

GUIDE BUSH, BRONZE

3120.71.

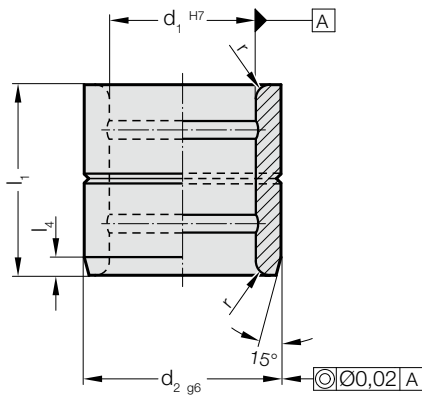

Material:

Bronze

Note:

Bushes can be used with radial or axial motion.

Assembly guide lines / Dimensional requirements and tolerances at the end of chapter D.

Fixing:

Connecting with adhesive or if needed secure with threaded pin or flat mushroom head screw 2192.61.

3120.71. Guide bush, Bronze

d ₁	45	45	45	50	50	50	55	60	60	63	65	70	70	75	75	80	80	85	90	100	110	120	125	130	140	150	160
d ₂	55	56	60	60	62	65	70	74	75	75	80	85	90	90	95	96	100	100	110	120	130	140	145	150	160	170	180
r	1.5	1.5	1.5	1.5	1.5	1.5	2	2	2	2	2	2	2	2	2	2	2	2	2	2	2	2	2	2	2	2	2
l ₄	4	4	4	4	4	4	4	4	4	4	4	4	4	4	4	4	4	4	4	4	4	4	4	4	4	4	4
l ₁																											
30	•	•	•	•	•	•		•	•																		
35	•	•	•	•	•	•		•	•			•															
40	•	•	•	•	•	•	•	•	•			•					•	•									
50	•	•	•	•	•	•	•	•	•			•		•			•	•									
60	•	•	•	•	•	•	•	•	•	•	•	•	•	•	•	•	•	•		•	•						
70			•	•	•	•	•	•	•	•	•	•	•	•	•	•	•	•		•	•						
80			•	•	•	•	•	•	•	•	•	•	•	•	•	•	•	•	•	•	•	•					
95				•																							
100					•				•				•		•	•	•	•		•	•	•	•	•	•	•	•
120											•						•	•		•	•	•	•	•	•		
130																									•		
140																		•			•	•			•		
150																										•	•

Ordering Code (example):

Guide bush, Bronze	=3120.71.
Diameter of conduit d ₁ 40 mm	= 040.
Outer diameter d ₂ 55 mm	= 055.
Installation length l ₁ 25 mm	= 025
Order No	=3120.71. 040. 055.025