



Mehrbereichs-Blindniet OPTO® Serie 10.618

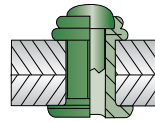

Edelstahl / Edelstahl

Flachkopf <
offen <

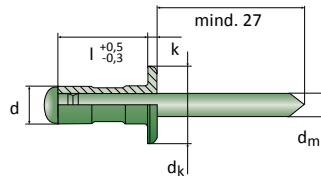

d	l +1		Nr.	
3,2	8,0	1,0 - 4,0	10.618.032.080	500
d_k 6,3	d_m 2,1	k 0,9	3,3 mm 1600 N	
4,0	10,0	1,0 - 4,5	10.618.040.100	500
	12,0	2,5 - 6,5	10.618.040.120	500
	15,0	4,5 - 9,5	10.618.040.150	500
d_k 7,9	d_m 2,8	k 1,3	4,1 mm 2700 N	

d	l +1		Nr.	
4,8	10,3	1,5 - 6,0	10.618.048.103	500
	12,7	2,5 - 7,5	10.618.048.127	500
	17,5	9,5 - 12,7	10.618.048.175	500
d_k 9,8	d_m 3,4	k 1,8	3,3 mm 3900 N	
6,4	15,0	1,5 - 7,0	10.618.064.150	250
	20,0	7,0 - 12,5	10.618.064.200	250
	25,0	12,0 - 17,5	10.618.064.250	250
d_k 12,7	d_m 4,0	k 2,7	6,5 mm 12500 N	

NEU

NEU

NEU

NEU