



Mehrbereichs-Blindniet OPTO®

Serie 10.600

 



Aluminium / Stahl

Senkkopf <
offen <



EN AW - 5052 [AlMg2,5]

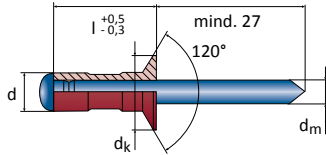

d	l +1		Nr.	
3,2	9,7	2,4 - 6,4	10.600.320.097	500
d _k 5,4	d _m 1,8	3,3 mm	670 N	900 N
4,0	11,3	2,9 - 7,9	10.600.400.113	500
d _k 6,5	d _m 2,3	4,1 mm	980 N	1320 N

d	l +1		Nr.	
4,8	12,0	4,0 - 8,0	10.600.480.120	500
	16,9	6,4 - 12,7	10.600.480.169	500
d _k 9,0	d _m 2,7	4,9 mm	1500 N	2300 N

NEU

NEU