




Mehrbereichs-Blindniet OPTO® Serie 10.600

Aluminium / Stahl

- > Flachkopf
- > offen

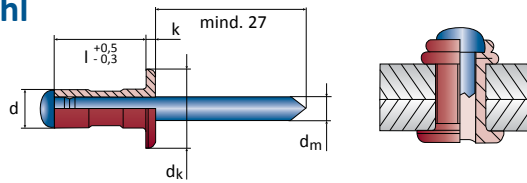

> lackiert weiss RAL 9010 **NEU**



EN AW - 5052 [AlMg2,5]

d	l +1		Nr.		
3,2	6,8	0,8 - 3,4	10.600.032.068 -9010	500	
	8,0	0,8 - 4,8	10.600.032.080 -9010	500	
	9,5	1,2 - 6,4	10.600.032.095 -9010	500	
	11,0	4,0 - 7,9	10.600.032.110 -9010	500	
d_k 6,4	d_m 1,8	k 1,0	3,3 mm	720 N	±1000 N
4,0	6,0	0,5 - 3,0	10.600.040.060 -9010	500	
	9,5	1,2 - 6,4	10.600.040.095 -9010	500	
	12,7	4,0 - 9,5	10.600.040.127 -9010	500	
	16,9	6,4 - 12,7	10.600.040.169 -9010	500	
d_k 7,9	d_m 2,3	k 1,2	4,1 mm	1120 N	±1650 N

d	l +1		Nr.		
4,8	10,3	1,6 - 6,4	10.600.048.103 -9010	500	
	15,1	4,8 - 11,1	10.600.048.151 -9010	500	
	16,9	6,4 - 12,7	10.600.048.169 -9010	500	
	24,8	12,7 - 19,8	10.600.048.248 -9010	500	
d_k 9,8	d_m 2,8	k 1,5	4,9 mm	1530 N	±2300 N

> lackiert schwarz RAL 9005 **NEU**



EN AW - 5052 [AlMg2,5]

d	l +1		Nr.		
3,2	6,8	0,8 - 3,4	10.600.032.068 -9005	500	
	8,0	0,8 - 4,8	10.600.032.080 -9005	500	
	9,5	1,2 - 6,4	10.600.032.095 -9005	500	
	11,0	4,0 - 7,9	10.600.032.110 -9005	500	
d_k 6,4	d_m 1,8	k 1,0	3,3 mm	720 N	±1000 N
4,0	6,0	0,5 - 3,0	10.600.040.060 -9005	500	
	9,5	1,2 - 6,4	10.600.040.095 -9005	500	
	12,7	4,0 - 9,5	10.600.040.127 -9005	500	
	16,9	6,4 - 12,7	10.600.040.169 -9005	500	
d_k 7,9	d_m 2,3	k 1,2	4,1 mm	1120 N	±1650 N

d	l +1		Nr.		
4,8	10,3	1,6 - 6,4	10.600.048.103 -9005	500	
	15,1	4,8 - 11,1	10.600.048.151 -9005	500	
	16,9	6,4 - 12,7	10.600.048.169 -9005	500	
	24,8	12,7 - 19,8	10.600.048.248 -9005	500	
d_k 9,8	d_m 2,8	k 1,5	4,9 mm	1530 N	±2300 N