 



# Sealed Blind Rivet CERTO®

 
## Series 10.902



EN AW - 5019 [AlMg5]

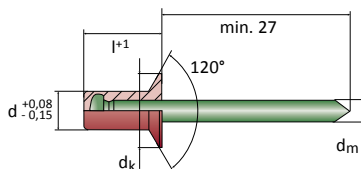

**Aluminium / Stainless Steel**



Countersunk Head <  
closed <

according to DIN EN ISO 15974

d	l +1		No.	
<b>4,0</b>	9,5	1,5 - 5,0	10.902.400.095	500
	11,0	4,0 - 6,5	10.902.400.110	500
	12,5	6,0 - 8,0	10.902.400.125	500
	14,5	7,5 - 10,0	10.902.400.145	500
<b>dk</b> 8,0 ±0,3	<b>dm</b> 2,2	4,1 mm	1650 N	2500 N

**NEU**