


Sealed Blind Rivet CERTO® Series 10.901

Aluminium / Aluminium



EN AW - 1050 A [Al 99,5]

- > Dome Head
- > closed

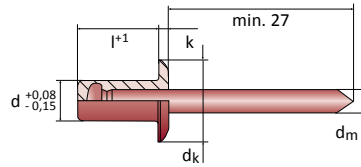

DIN EN ISO 15975

d	l +1		No.		
3,2	8,0	0,5 - 3,5	10.901.032.080	500	
	9,5	3,5 - 5,0	10.901.032.095	500	
d_k 6,0 ± 0,3	d_m 1,9	k 1,1 ± 0,15	3,3 mm	520 N	540 N
4,0	9,5	0,5 - 5,0	10.901.040.095	500	
	12,5	4,5 - 8,0	10.901.040.125	500	
d_k 8,0 ± 0,4	d_m 2,2	k 1,3 ± 0,2	4,1 mm	720 N	760 N

d	l +1		No.		
4,8	9,5	1,0 - 4,5	10.901.048.095	500	
	11,5	4,0 - 6,5	10.901.048.115	500	
	14,5	6,5 - 9,5	10.901.048.145	500	
	18,0	9,0 - 13,0	10.901.048.180	500	
d_k 9,5 ± 0,4	d_m 2,7	k 1,5 ± 0,2	4,9 mm	1000 N	1400 N