




Standard Blindniet ALFO® Serie 10.713

Edelstahl A4 / Edelstahl A4/A5



[1.4404]

- > Flachkopf
- > offen

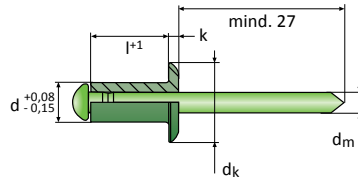

entsprechend DIN EN ISO 15983

d	l +1		Nr.		
3,0	6,0	0,5 - 3,0	10.713.030.060	500	
	8,0	3,0 - 5,0	10.713.030.080	500	
	10,0	5,0 - 7,0	10.713.030.100	500	
	12,0	6,5 - 8,5	10.713.030.120	500	
d_k 6,3 -0,7	d_m 1,9	k 0,8 ±0,2	3,1 mm	1760 N	2270 N
4,0	6,0	1,0 - 2,5	10.713.040.060	500	
	8,0	2,5 - 4,5	10.713.040.080	500	
	10,0	4,5 - 6,5	10.713.040.100	500	
	12,0	6,5 - 8,5	10.713.040.120	500	
	16,0	8,5 - 12,0	10.713.040.160	500	
d_k 8,0 -1,0	d_m 2,5	k 1,0 ±0,3	4,1 mm	3220 N	4250 N

d	l +1		Nr.		
5,0	8,0	2,0 - 4,0	10.713.050.080	500	
	10,0	4,0 - 6,0	10.713.050.100	500	
	12,0	6,0 - 8,0	10.713.050.120	500	
	16,0	9,5 - 11,0	10.713.050.160	500	
	18,0	11,0 - 13,0	10.713.050.180	500	
	20,0	13,0 - 15,0	10.713.050.200	500	
	25,0	15,0 - 20,0	10.713.050.250	250	
30,0	20,0 - 25,0	10.713.050.300	250		
d_k 9,5 -0,8	d_m 3,2	k 1,1 ±0,3	5,1 mm	4800 N	6600 N

NEU

NEU

NEU