





Blindnietmutter SFM-R

Serie 10.842



Stahl

 Flachkopf <
Rundschaft <
offen <
gerändelt <

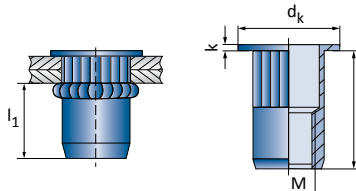

C4C [1.0303]

M		I	Nr.	
M4	0,5 - 2,5	9,5	10.842.040.250	500
	2,5 - 4,5	13,8	10.842.040.450	500
D 6,0	k 0,8	dk 9,0	l₁ max. 8,0	↓ 5000 N
M5	0,5 - 3,0	12,0	10.842.050.300	500
	2,5 - 5,0	15,0	10.842.050.500	500
D 7,0	k 1,0	dk 10,0	l₁ max. 9,0	↓ 9000 N
M6	0,5 - 3,0	14,5	10.842.060.300	500
	3,5 - 5,5	19,0	10.842.060.550	500
D 9,0	k 1,5	dk 13,0	l₁ max. 11,0	↓ 13500 N

NEU

NEU

M		I	Nr.	
M8	0,5 - 3,0	16,0	10.842.080.300	250
	3,0 - 5,5	18,5	10.842.080.550	250
D 11,0	k 1,5	dk 16,0	l₁ max. 13,5	↓ 20000 N
M10	1,0 - 3,0	22,5	10.842.100.300	250
	3,0 - 4,5	24,0	10.842.100.450	250
D 13,0	k 2,0	dk 19,0	l₁ max. 16,5	↓ 28000 N
M12	1,0 - 4,0	27,0	10.842.120.400	100
D 16,0	k 2,0	dk 23,0	l₁ max. 18,5	↓ 45000 N

NEU

NEU