




Blind Rivet Nut ASM-G

Series 10.855

Aluminium

- > Countersunk Head
- > Round Shank
- > Closed

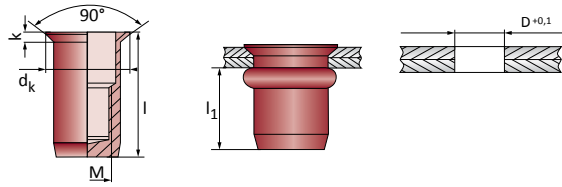

EN AW - 5754 [AlMg3]

M		l	No.		
M5	1,5 - 4,0	19,5	10.855.050.400	500	
D 7,0	k 1,5	d_k 9,3	l₁ max. 15,5	4 Nm	4300 N
M6	1,5 - 4,5	23,5	10.855.060.450	500	
D 9,0	k 1,5	d_k 11,3	l₁ max. 18,5	6 Nm	6700 N

M		l	No.		
M8	1,5 - 4,5	28,0	10.855.080.450	500	
	4,5 - 6,0	29,5	10.855.080.600	500	
D 11,0	k 1,5	d_k 13,3	l₁ max. 23,0	18 Nm	11000 N