




Blind Rivet Nut ESM KLSK A4

Series 10.802/79 **NEW**

Stainless Steel A4

- > Small Countersunk Head
- > Round Shank
- > Open

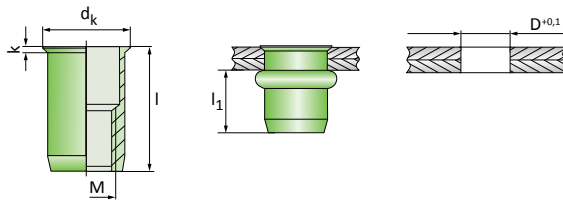

M		l	No.		
M4	0,5 - 2,0	10,0	10.802.040.200/79	500	
D 6,0	k 0,5	dk 6,8	l1 max. 8,0	3 Nm	6500 N
M5	0,5 - 2,5	12,0	10.802.050.250/79	500	
D 7,0	k 0,6	dk 8,0	l1 max. 8,5	6 Nm	10000 N

NEW

NEW

M		l	No.		
M6	0,5 - 3,0	10,0	10.802.060.300/79	500	
D 9,0	k 0,6	dk 10,0	l1 max. 10,0	11 Nm	15000 N
M8	1,0 - 4,0	16,5	10.802.080.400/79	500	
D 11,0	k 0,6	dk 12,0	l1 max. 11,5	20 Nm	25000 N

NEW

NEW