



Blind Rivet Nut **ESM-KLSK-G**

Series 10.840



Stainless Steel A2

 Small Countersunk Head <
Round Shank <
Closed <

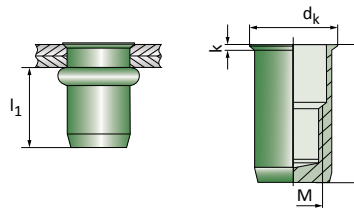

[1.4567]

M		l	No.		
M4	0,5 - 2,5	16,0	10.840.040.250	500	
D 6,0	k 0,5	dk 7,0	li max. 13,0	4 Nm	7000 N
M5	0,5 - 3,0	18,0	10.840.050.300	500	
D 7,0	k 0,5	dk 8,0	li max. 14,5	6 Nm	11000 N
M6	0,5 - 3,0	21,0	10.840.060.300	500	
D 9,0	k 0,5	dk 10,0	li max. 16,0	11 Nm	18000 N

M		l	No.		
M8	0,5 - 3,0	23,5	10.840.080.300	500	
D 11,0	k 0,5	dk 12,0	li max. 19,0	24 Nm	27000 N
M10	1,0 - 3,5	26,5	10.840.100.350	200	
D 13,0	k 0,7	dk 14,0	li max. 22,0	50 Nm	40000 N