




Blind Rivet Nut UNIVERSAL

Series 10.873



Stainless Steel A2

  Small Countersunk Head <
Round Shank <
Open <

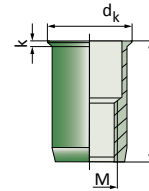

[1.4567]

M		l	No.		
M4	0,5 - 3,0	10,5	10.873.400.000	500	
D 7,0	k 0,4	dk 8,0	l₁ max. 8,0	3 Nm	7000 N
M5	0,5 - 3,0	11,5	10.873.500.000	500	
D 7,0	k 0,4	dk 8,0	l₁ max. 8,5	5 Nm	11000 N

M		l	No.		
M6	0,5 - 3,0	13,0	10.873.600.000	500	
D 8,0	k 0,4	dk 9,0	l₁ max. 10,0	10 Nm	18000 N
M8	0,5 - 3,0	15,5	10.873.800.000	500	
D 10,0	k 0,4	dk 11,0	l₁ max. 11,5	20 Nm	27000 N