





Blind Rivet Nut HEXATOP®-E-KLSK-G

Series 10.805



Stainless Steel A2

   Small Countersunk Head <
Partial Hexagonal Shank <
Closed <

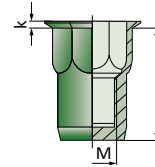

[1.4567]

M		I	No.		
M4	0,5 - 2,5	16,0	10.805.040.250	500	
SW 6,0	SW² 6,8	k 0,5	l₁ max. 10,5	⌀ 5 Nm	↓ 6000 N
M5	0,5 - 3,0	18,0	10.805.050.300	500	
SW 7,0	SW² 7,8	k 0,6	l₁ max. 12,5	⌀ 7 Nm	↓ 9500 N

NEW

M		I	No.		
M6	0,5 - 3,0	21,0	10.805.060.300	500	
SW 9,0	SW² 9,8	k 0,7	l₁ max. 16,0	⌀ 13 Nm	↓ 16000 N
M8	0,5 - 3,0	23,5	10.805.080.300	250	
SW 11,0	SW² 11,8	k 0,7	l₁ max. 17,5	⌀ 25 Nm	↓ 26000 N