





Blind Rivet Nut HEXATOP® KLSK

Series 10.893



Steel

   Small Countersunk Head <
Partial Hexagonal Shank <
Open <

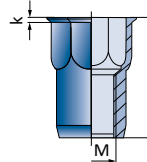

C4C [1.0303]

M		I	No.			
M4	0,5 - 2,0	10,0	10.893.040.200			500
SW 6,3	SW² 7,0	k 0,4	l₁ max. 7,5	4 Nm	3800 N	
M5	0,6 - 3,0	12,5	10.893.050.300			500
SW 7,2	SW² 8,0	k 0,5	l₁ max. 9,0	6 Nm	6000 N	
M6	0,5 - 3,0	15,5	10.893.060.300			500
	1,5 - 4,0	15,5	10.893.060.400			500
SW 9,6	SW² 10,5	k 0,5	l₁ max. 11,5	11 Nm	9500 N	

NEW

M		I	No.			
M8	0,5 - 3,0	18,0	10.893.080.300			250
SW 10,6	SW² 11,5	k 0,6	l₁ max. 14,0	24 Nm	12500 N	
M10	1,0 - 4,0	22,5	10.893.100.400			250
SW 12,7	SW² 14,4	k 0,8	l₁ max. 16,0	50 Nm	37000 N	