
 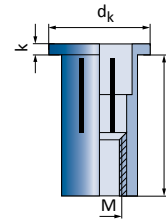
 


Folding Blind Rivet Nut SFM-PL

Series 10.816



Steel

- Flat Head <
- Round Shank <
- Open <
- Slotted <

C4C [1.0303]

M			l	No.		
M6	0,5 - 7,1	10,0 - 10,15	25,8 ^{-0,8}	10.816.060.710	12 Nm	15000 N
D 9,8^{-0,45}	k 1,6^{-0,25}	dk 16,4^{-0,1}	l1 max. 11,7			
M8	0,5 - 7,1	12,7 - 12,85	29,6 ^{-1,0}	10.816.080.710	21 Nm	27000 N
D 12,6^{-0,1}	k 1,7^{-0,25}	dk 19,6^{-0,8}	l1 max. 13,6			

