


Lead screw support blocks

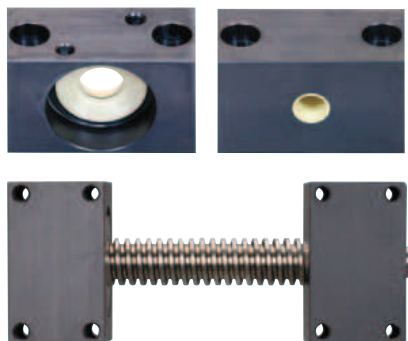

Order Key

SLS-10x2-LL



Accessories


► drylin® Drive Technology,
page 1203




► page 1227

i Scope of delivery: anodized support block with clamp rings and plain bearings (fixed and floating side)

fixed bearing

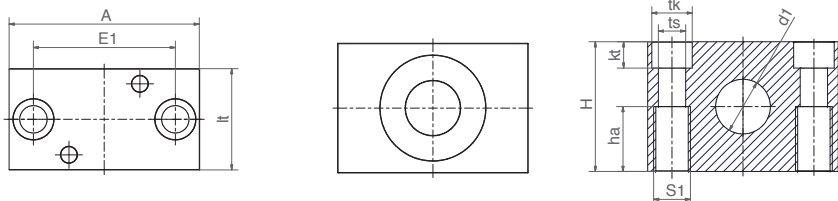

floating bearing

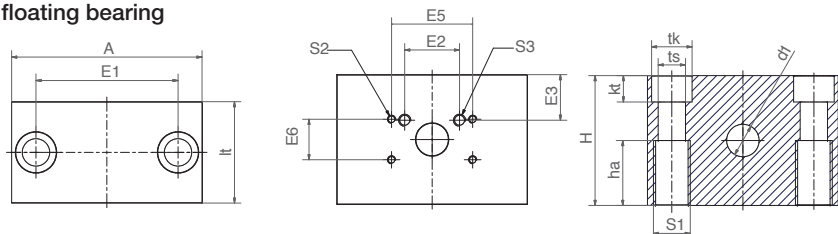

Technical Data and Dimensions [mm]

Part number	Weight [g]	max. stat. F axial [N]	S1	S2	S3
SLS-10x2-LL	115	-	M8	M4	M6
SLS-10x2-FL	88	700	M8	-	-
SLS-10x3-LL	115	-	M8	M4	M6
SLS-10x3-FL	88	700	M8	-	-
SLS-10x12-LL	115	-	M8	M4	M6
SLS-10x12-FL	88	700*	M8	-	-
SLS-10x50-LL	115	-	M8	M4	M6
SLS-10x50-FL	88	700*	M8	-	-
SLS-18x4-LL	295	-	M0	M4	M6
SLS-18x4-FL	205	1,600	M0	-	-
SLS-18x8P4-LL	295	-	M0	M4	M6
SLS-18x8P4-FL	205	1,600	M0	-	-
SLS-18x24-LL	295	-	M0	M4	M6
SLS-18x24-FL	205	1,600*	M0	-	-
SLS-18x100-LL	295	-	M0	M4	M6
SLS-18x100-FL	205	1,600*	M0	-	-
SLS-24x5-LL	725	-	M16	M4	M6
SLS-24x5-FL	525	2,500	M16	-	-

Part number	A	H	E1	E2	E3	E5	E6	lt	kt	tk	ts	d1	ha
SLS-10x2-LL	50	32	36	27	6.5	40	20	30	6.5	11	6.6	10	16
SLS-10x2-FL	50	32	36	-	-	-	-	30	6.5	11	6.6	10	16
SLS-10x3-LL	50	32	36	27	6.5	40	20	30	6.5	11	6.6	10	16
SLS-10x3-FL	50	32	36	-	-	-	-	30	6.5	11	6.6	10	16
SLS-10x12-LL	50	32	36	27	6.5	40	20	30	6.5	11	6.6	10	16
SLS-10x12-FL	50	32	36	-	-	-	-	30	6.5	11	6.6	10	16
SLS-10x50-LL	50	32	36	27	6.5	40	20	30	6.5	11	6.6	10	16
SLS-10x50-FL	50	32	36	-	-	-	-	30	6.5	11	6.6	10	16
SLS-18x4-LL**	72	46	54	27	13.5	40	20	36	8.6	15	9	18	23
SLS-18x4-FL	72	46	54	-	-	-	-	36	8.6	15	9	18	23
SLS-18x8P4-LL**	72	46	54	27	13.5	40	20	36	8.6	15	9	18	23
SLS-18x8P4-FL	72	46	54	-	-	-	-	36	8.6	15	9	18	23
SLS-18x24-LL**	72	46	54	27	13.5	40	20	36	8.6	15	9	18	23
SLS-18x24-FL***	72	46	54	-	-	-	-	36	8.6	15	9	18	23
SLS-18x100-LL**	72	46	54	27	13.5	40	20	36	8.6	15	9	18	23
SLS-18x100-FL***	72	46	54	-	-	-	-	36	8.6	15	9	18	23
SLS-24x5-LL**	94	64	70	27	22.5	40	20	50	13	20	13.5	24	32
SLS-24x5-FL	94	64	70	-	-	-	-	50	13	20	13.5	24	32

* Can exceed max. stat. load of the nut

** Must be turned to dimension d1 *** Must be turned to 18 mm

delivery from stock
time

prices price list online
www.igus.eu/eu/sls-ll