

4 Hybrid-Doppelrollen-Lager
4 hybrid double roller bearings

... Leichtlauf ...

drylin® W-Hybridschlitten in 3 Längen und in 3 Breiten

Das Prinzip gleiten und rollen überzeugt in vielen Anwendungen bei denen es auf eine leichte und leise Verstellung ankommt. Passend auf die drylin® W-Doppelwellenprofile in Baugröße 10/16/20 sind ab sofort Komplettschlitten mit 4 vormontierten drylin® W-Doppelhybridlagern lieferbar.

- Vormontierte Schlitten mit 4 Hybridlagern
- Aufnahme von Querkräften möglich
- Schlitten in Längen 100/150/200 mm
- Alle Schlitten optional mit Handklemmung
- Schmierfreie und leise Verstellungen

Typische Anwendungsbereiche:

Schutztüren, Ladeneinrichtungen, Sitzverstellungen, ...



drylin® W hybrid carriages available in 3 lengths and 3 widths

The gliding and rolling system exhibits a convincing performance in many applications which require an easy and low noise adjustment. Suitable for drylin® W double shaft profiles in sizes 10/16/20, the complete carriage with 4 pre-assembled drylin® W-hybrid bearings is immediately available.

- Pre-assembled carriage with 4 integrated hybrid bearings
- Absorption of transverse forces possible
- Carriage lengths: 100/150/200 mm
- All carriages with manual hand clamp (optional)
- Lubricant free and quiet adjustments

Typical application areas:

Safety doors, shop fittings, seat adjusters, ...

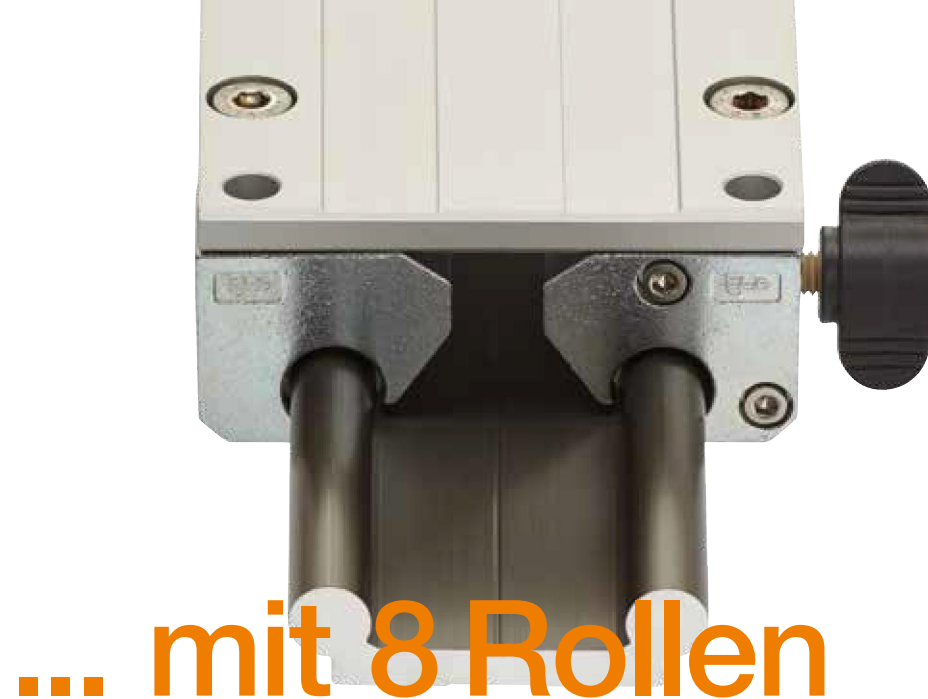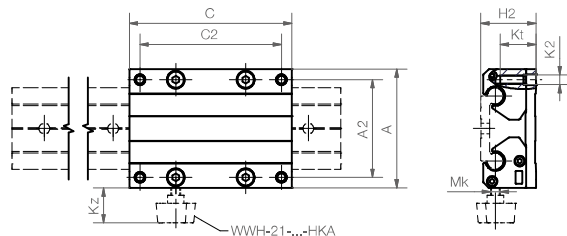

... mit 8 Rollen

Abmessungen Dimensions [mm]

Bestellnr. Part No.	Gewicht Weight [kg]	A Breite Width	C Länge Length	A2	C2	K2	Kt	H2	stat. Tragfähigkeit stat. load capacity Coy [N]
WWH-21-10-40-10	0,59	73	100	60	87	M6	21	34	1,400
WWH-21-10-40-15	0,64	73	150	60	137	M6	21	34	1,400
WWH-21-10-40-20	0,70	73	200	60	187	M6	21	34	1,400
WWH-21-10-80-10	0,64	107	100	94	87	M6	21	34	1,400
WWH-21-10-80-15	0,72	107	150	94	137	M6	21	34	1,400
WWH-21-10-80-20	0,80	107	200	94	187	M6	21	34	1,400
WWH-21-10-120-10	0,71	153	100	140	87	M6	21	34	1,400
WWH-21-10-120-15	0,84	153	150	140	137	M6	21	34	1,400
WWH-21-10-120-20	0,96	153	200	140	187	M6	21	34	1,400
WWH-21-16-60-10	1,31	104	100	86	82	M8	29	49	2,400
WWH-21-16-60-15	1,44	104	150	86	132	M8	29	49	2,400
WWH-21-16-60-20	1,57	104	200	86	182	M8	29	49	2,400
WWH-21-20-80-15	1,72	134	100	116	132	M8	24	57	3,360
WWH-21-20-80-20	1,82	134	150	116	182	M8	24	57	3,360
WWH-21-20-80-25	2,02	134	200	116	232	M8	24	57	3,360

Optional mit Handklemmung verfügbar
Manual clamping available

Bestellnummer Part No.
WWH-21-...-HKA

Lieferbar Available
ab Lager from stock

www.igus.de/WWH-21
www.igus.eu/WWH-21