

3/8 Zoll-Bohrung für Kameras
3/8 Zoll-Bohrung für Kameras



leicht rollen & klemmen – ruckelfrei filmen

Neuer Camera Slider mit Doppelrolle und Klemmung

Ab sofort im drylin® W Linearbaukasten verfügbar sind die neuen Camera Slider mit Hybridlager und integrierter Handklemmungsfunktion für den "Do-It-Yourself Bereich". Die vormontierten Schlitten haben mittig eine ø 10 mm-Durchgangsbohrung für die Befestigung der Kamera. Durch die Doppelrollenlager und diverse Schienenbreiten bieten die Schlitten eine breite Auflagefläche für viele Kameratypen.

- Komplett vormontierter Schlitten
- Leichte ruckelfreie Verstellung
- Leiser Lauf
- Leicht durch Aluminium und Kunststoff

Typische Anwendungsbereiche:
Kameraverstellungen und -fahrten, ...


New camera slider with double roller and clamp

Now available in the drylin® W linear system, the new camera slide with hybrid bearings and integrated hand clamping function is intended for the Do-It-Yourself area. The pre-assembled carriage has at the centre a 3/8 inch through-hole (ø10mm) for mounting the camera. Because of the double roller bearings and various rail widths, the carriages offer a wide load bearing surface for many types of cameras.

- Complete pre-assembled carriage
- Easy, jerk-free adjustment
- Quiet operation
- Lightweight due to the use of plastics and aluminium

Typical application areas:

Camera adjustments and movements, ...

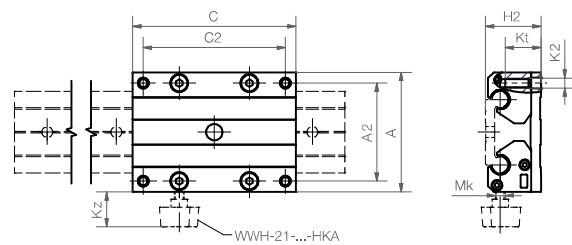

Abmessungen Dimensions [mm]

Bestellnr. Part No.	Gewicht Weight [kg]	A	C	A2	C2	K2	Kt	H2	stat. Trag- fähigkeit stat. load capacity Coy [N]
		Breite Width	Länge Length						
WWH-21-10-40-10-SL	0,59	73	100	60	87	M6	21	34	1.400
WWH-21-10-40-15-SL	0,64	73	150	60	137	M6	21	34	1.400
WWH-21-10-40-20-SL	0,70	73	200	60	187	M6	21	34	1.400
WWH-21-10-80-10-SL	0,64	107	100	94	87	M6	21	34	1.400
WWH-21-10-80-15-SL	0,72	107	150	94	137	M6	21	34	1.400
WWH-21-10-80-20-SL	0,80	107	200	94	187	M6	21	34	1.400
WWH-21-16-60-10-SL	1,31	104	100	86	82	M8	29	49	2.400
WWH-21-16-60-15-SL	1,44	104	150	86	132	M8	29	49	2.400
WWH-21-16-60-20-SL	1,57	104	200	86	182	M8	29	49	2.400
WWH-21-20-80-15-SL	1,72	134	100	116	132	M8	24	57	3.360
WWH-21-20-80-20-SL	1,82	134	150	116	182	M8	24	57	3.360
WWH-21-20-80-25-SL	2,02	134	200	116	232	M8	24	57	3.360

Optional mit Handklemmung verfügbar
Manual clamping available

Bestellnummer Part No.
WWH-21-...-SL-HK

Lieferbar Available
ab Lager from stock

www.igus.de/WWH-21-SL
www.igus.eu/WWH-21-SL